


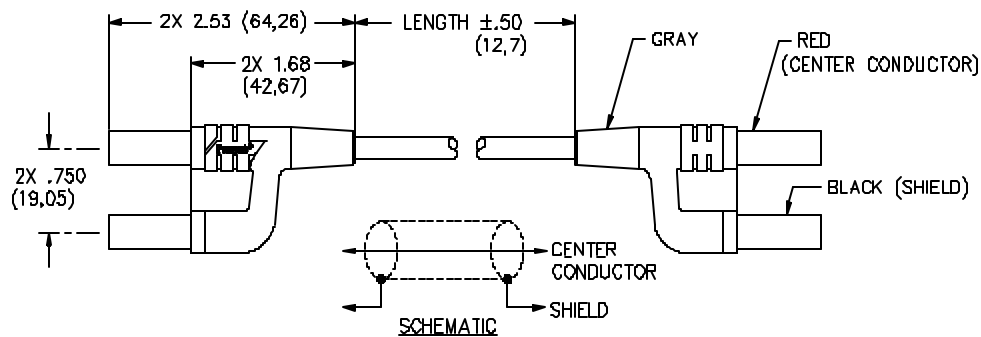

FEATURES:

- Cable is designed to be used with all standard .166" or 4mm diameter shrouded banana jacks spaced at .75" (19mm).
- Pomona's double banana plugs can be used with most digital multimeters.
- Offset design and color-coded black and red safety shrouds eliminate wrong polarity connections.
- Manufactured to comply with the latest safety standards.
- Molded strain relief increases reliability and durability of the cable.

MATERIALS:

Banana Plugs:

Body: Brass, Nickel Plated.

Springs: Beryllium Copper, Nickel Plated.

Inner Insulation: Polypropylene.

Insulation: Santoprene.

Safety Shrouds: Nylon, black and red.

Cable: RG58C/U, .195 (5,0) O.D., 50 OHMS Color: Black.

Marking: POMONA 6283-C-XX®

RATINGS:

IEC-1010-2-031, Category II, P2 compliant.

Operating Temperature: +55°C (+131°F) Max.

Operating Voltage: 600 VRMS.

ORDERING INFORMATION: Model 6283-C-XX

XX = Cable Length. See current catalog for available lengths.

Ordering Example: 6283-C-12 Cable length is 12" (304,8) Cable is RG58C/U, .195 (5,0) color is black.

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ± .005" (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies. Made in USA