


Han TC350 Buchsenkontakt 95mm²

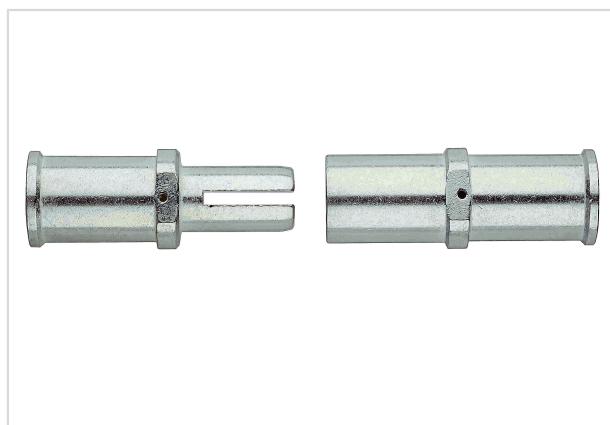

Part number	09 11 000 6243
Specification	Han TC350 Buchsenkontakt 95mm ²
HARTING eCatalogue	https://b2b.harting.com/09110006243

Image is for illustration purposes only. Please refer to product description.

Identification

Category	Contacts
Series	TC 350
Type of contact	Crimp contact

Version

Gender	Female
Manufacturing process	Turned contacts

Technical characteristics

Conductor cross-section	95 mm ²
Operating current	≤350 A
Contact resistance	≤0.3 mΩ
Stripping length	30 mm
Limiting temperature	-40 ... +125 °C
Mating cycles	≥500

Material properties

Material (contacts)	Copper alloy
Surface (contacts)	Silver plated
RoHS	compliant with exemption
RoHS exemptions	6(c): Copper alloy containing up to 4 % lead by weight
ELV status	compliant with exemption
China RoHS	50

Material properties

REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	Yes
REACH SVHC substances	Lead
ECHA SCIP number	b51e5b97-eeb5-438b-8538-f1771d43c17d
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead

Specifications and approvals

Specifications	EN 60664-1 IEC 61984
----------------	-------------------------

Commercial data

Packaging size	1
Net weight	84.34 g
Country of origin	Romania
European customs tariff number	85359000
eCl@ss	27440204 Contact for industrial connectors