
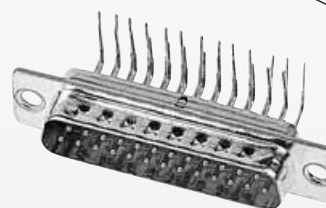


9-50

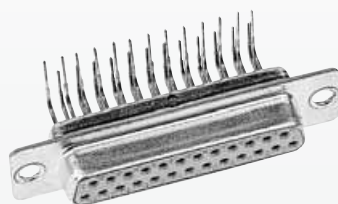

Original Versions

D-Sub - S

Identification	No. of contacts	Part No.																															
Performance levels Explanations see page 02.02 Other performance levels on request		Performance level 3	Performance level 2																														
Male connector metal shell with dimples	9 15 25 37 50	2.84 mm pitch 09 67 009 5663 09 67 015 5663 09 67 025 5663 09 67 037 5663 09 67 050 5663 2.54 mm pitch 09 67 009 5657 ²⁾ 09 67 015 5657 ²⁾ 09 67 025 5657 ²⁾ 09 67 037 5657 ²⁾ 09 67 050 5657 ²⁾	2.84 mm pitch 09 67 009 5664 09 67 015 5664 09 67 025 5664 09 67 037 5664 09 67 050 5664 ²⁾ 2.54 mm pitch 09 67 009 5658 ²⁾ 09 67 015 5658 ²⁾ 09 67 025 5658 ²⁾ 09 67 037 5658 ²⁾ 09 67 050 5658 ²⁾																														
Female connector metal shell	9 15 25 37 50	2.84 mm pitch 09 67 009 4763 09 67 015 4763 09 67 025 4763 09 67 037 4763 09 67 050 4763 2.54 mm pitch 09 67 009 4757 ²⁾ 09 67 015 4757 ²⁾ 09 67 025 4757 ²⁾ 09 67 037 4757 ²⁾ 09 67 050 4757 ²⁾	2.84 mm pitch 09 67 009 4764 09 67 015 4764 09 67 025 4764 09 67 037 4764 09 67 050 4764 ²⁾ 2.54 mm pitch 09 67 009 4758 ²⁾ 09 67 015 4758 ²⁾ 09 67 025 4758 ²⁾ 09 67 037 4758 ²⁾ 09 67 050 4758 ²⁾																														
Male connector	9-37 50	<table><tr><th></th><th>a</th><th>b ±0.1</th><th>c</th><th>f</th></tr><tr><td>9</td><td>30.9</td><td>25.0</td><td>12.5</td><td>2.74</td></tr><tr><td>15</td><td>39.2</td><td>33.3</td><td>12.5</td><td>2.74</td></tr><tr><td>25</td><td>53.1</td><td>47.0</td><td>12.5</td><td>2.76</td></tr><tr><td>37</td><td>69.4</td><td>63.5</td><td>12.5</td><td>2.76</td></tr><tr><td>50</td><td>67.0</td><td>61.1</td><td>15.4</td><td>2.76</td></tr></table>			a	b ±0.1	c	f	9	30.9	25.0	12.5	2.74	15	39.2	33.3	12.5	2.74	25	53.1	47.0	12.5	2.76	37	69.4	63.5	12.5	2.76	50	67.0	61.1	15.4	2.76
	a	b ±0.1	c	f																													
9	30.9	25.0	12.5	2.74																													
15	39.2	33.3	12.5	2.74																													
25	53.1	47.0	12.5	2.76																													
37	69.4	63.5	12.5	2.76																													
50	67.0	61.1	15.4	2.76																													
Female connector		<table><tr><th></th><th>a</th><th>b ±0.1</th><th>c</th><th>f</th></tr><tr><td>9</td><td>30.9</td><td>25.0</td><td>12.5</td><td>2.74</td></tr><tr><td>15</td><td>39.2</td><td>33.3</td><td>12.5</td><td>2.74</td></tr><tr><td>25</td><td>53.1</td><td>47.0</td><td>12.5</td><td>2.76</td></tr><tr><td>37</td><td>69.4</td><td>63.5</td><td>12.5</td><td>2.76</td></tr><tr><td>50</td><td>67.0</td><td>61.1</td><td>15.4</td><td>2.76</td></tr></table>			a	b ±0.1	c	f	9	30.9	25.0	12.5	2.74	15	39.2	33.3	12.5	2.74	25	53.1	47.0	12.5	2.76	37	69.4	63.5	12.5	2.76	50	67.0	61.1	15.4	2.76
	a	b ±0.1	c	f																													
9	30.9	25.0	12.5	2.74																													
15	39.2	33.3	12.5	2.74																													
25	53.1	47.0	12.5	2.76																													
37	69.4	63.5	12.5	2.76																													
50	67.0	61.1	15.4	2.76																													

Dimensions in mm

Dimensions in mm

Mating conditions see page 02.02
Accessories see page 02.11
Board drillings see page 02.11