

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1731120021](#)
Status: **Active**
Overview: [FCT D-Sub Connectors](#)
Description: FCT Stamped Contact, Female, Crimp, 0.10µm Gold Plating, Split Tine, 20-24 AWG


Documents:
[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General
Product Family D-Sub Products
Series [173112](#)
Contact Type Stamped Crimp
Overview [FCT D-Sub Connectors](#)
Product Category Contacts
Product Name FCT Products
Type Standard Density
UPC 889056291187

Physical
Durability (mating cycles max) 50
Gender Female
Material - Contact Copper Alloy
Net Weight 0.200/g
Orientation Straight
Packaging Type Reel
Plating - Contact Gold over Nickel
Plating min - Mating 0.100µm
Temperature Range - Operating -55° to +125°C
Termination Style Crimp
Wire Size AWG 20, 22, 24

Electrical
Current - Maximum per Contact 5.0A

Material Info
Engineering Number S7LR

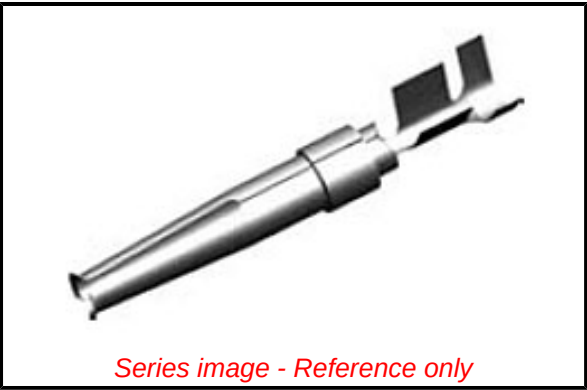

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[173112](#) Series

Use With
FCT Standard-Density Connectors

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION