


Sales Outline DrawingRevision **A**

**May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.**

NO CIRCUITRY

Oscillation Frequency (Hz)	2730
Operating Voltage (Vp-p)	4.0 – 6.0
Rated Voltage (Vp-p)	5.0
Current Consumption Max. (mA)	90 at Rated Voltage
Sound Pressure Level (dB/min)	85 at 10cm at Rated Voltage
Coil Resistance (Ω)	32 ± 4
Operating Temperature ($^{\circ}\text{C}$)	$-30 \sim +70$
Storage Temperature ($^{\circ}\text{C}$)	$-40 \sim +85$
Housing	LCP plastic resin (Color: Black)
Weight (Grams)	0.8
Condition by wave soldering ($^{\circ}\text{C}$)	250 ± 5 / within 5 sec
Condition by hand soldering ($^{\circ}\text{C}$)	350 ± 20 / within 5 sec
Options	For other options contact factory

Dimensions: (units: mm) **TOL:** ± 0.5 **PS:** Vp-p = 1/2duty, square wave **RoHS Compliant**

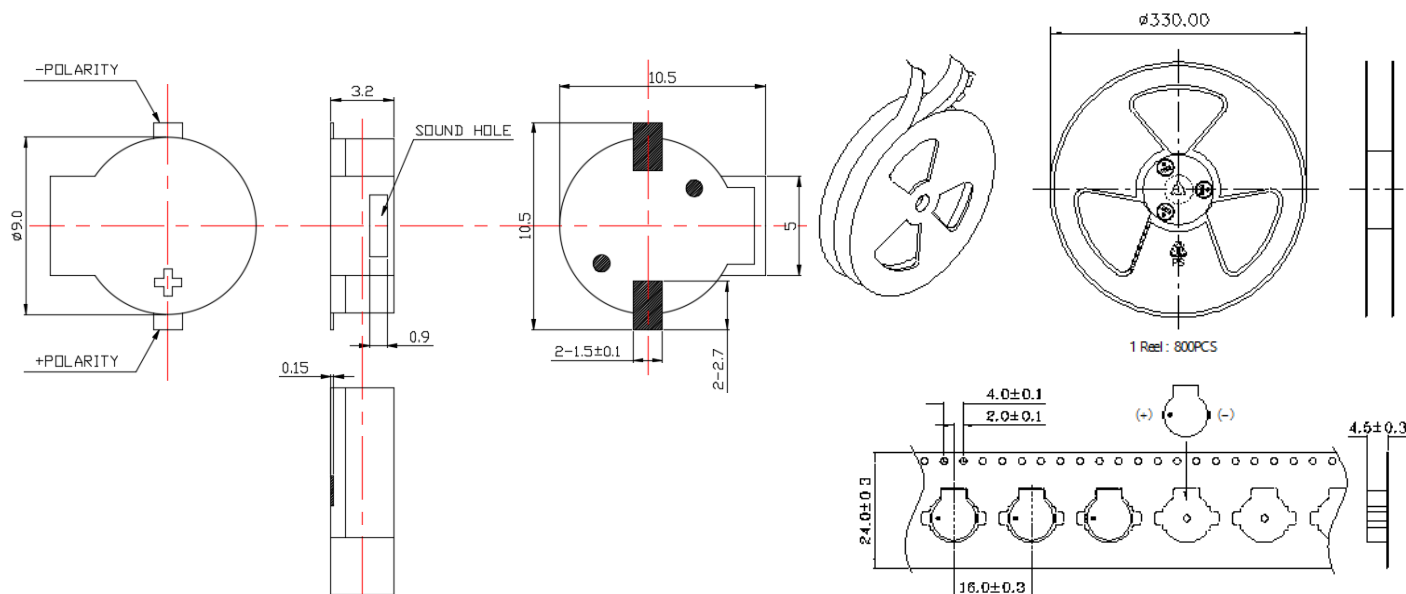

Packaging: Parts are supplied on tape and reel.

Units do not come with wash label and are not appropriate for aqueous wash.