


### DIN32

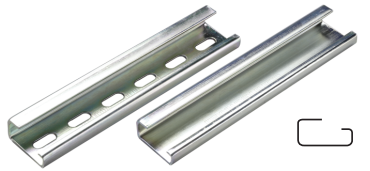


32 mm x  
15 mm deep

#### Zinc Plated Steel

| Type         | Cat. No.   | Length | Std. Pk. |
|--------------|------------|--------|----------|
| Perforated   | 2511160    | 2m     | 10       |
|              | 2511160/1M | 1m     | 20       |
| Unperforated | 2511150    | 2m     | 10       |
|              | 2511150/1M | 1m     | 20       |

### DIN15

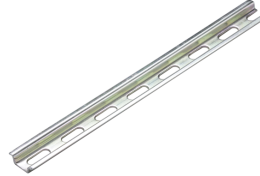


15 mm x  
5.5 mm deep

#### Zinc Plated Steel


| Type       | Cat. No. | Length | Std. Pk. |
|------------|----------|--------|----------|
| Perforated | CA601/S  | 1m     | 50       |

### Dimensions

#### Perforated Steel

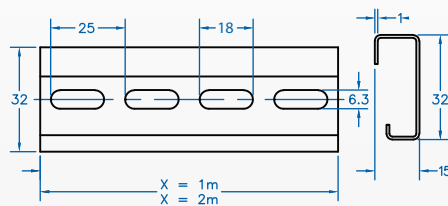

#### Perforated Steel

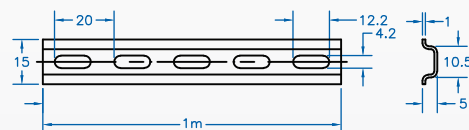

#### Unperforated Steel

