



Order Code	TCK-100
Inductance	8.2 μ H $\pm$ 20% (at 100 kHz / 250 mV)
Impedance (DCR)	39 m Ω max.
Rated Current	5 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions

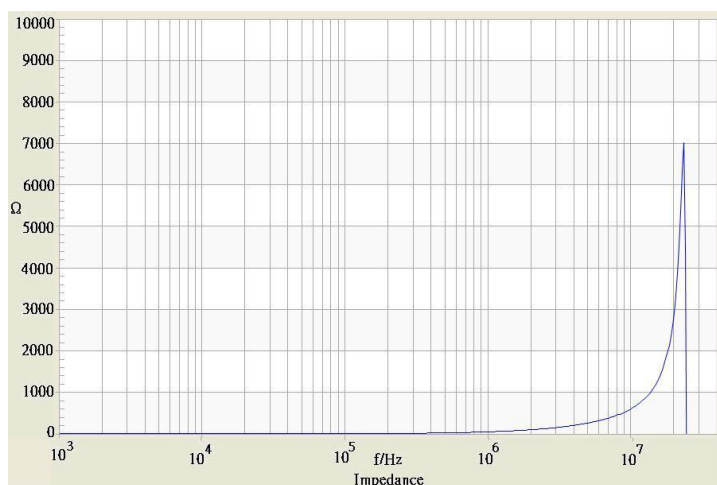

Impedance Curve



Outline Dimensions

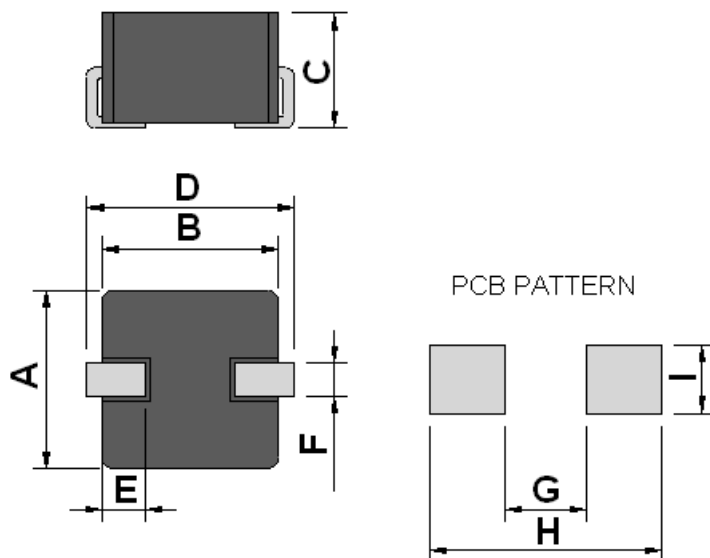

Dimensions [mm]	
A	6.5 $\pm$ 0.3
B	6.5 $\pm$ 0.3
C	4.2 max.
D	7.6 max.
E	1.6 $\pm$ 0.3
F	1.2 $\pm$ 0.3
G	3.0
H	8.5
I	2.5

All specifications valid at +25°C, unless otherwise stated.