

## Han-Eco Mod.24-profile seal-HBM

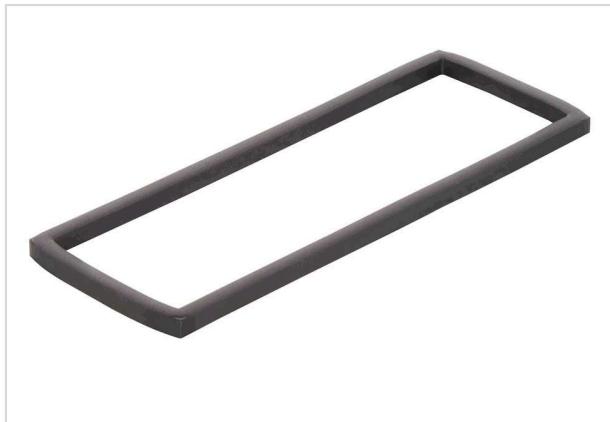


Image is for illustration purposes only. Please refer to product description.

Part number	19 41 000 9904
Specification	Han-Eco Mod.24-profile seal-HBM
HARTING eCatalogue	<a href="https://b2b.harting.com/19410009904">https://b2b.harting.com/19410009904</a>

### Identification

Category	Accessories
Series of hoods/housings	Han-Eco® Modular
Type of accessory	Profile gasket

### Version

Size	24 B
------	------

### Material properties

Material (seal)	NBR
Colour (seal)	Black
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Naphthalene
Fire protection on railway vehicles	EN 45545-2 (2020-08)
Requirement set with Hazard Levels	R22 (HL 1-3) R23 (HL 1-3)

## Commercial data

Packaging size	10
Net weight	5.2 g
Country of origin	Germany
European customs tariff number	40169300
GTIN	5713140130654
ETIM	EC002943
eCl@ss	27440291 Connector component (parts)