

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [5601240131](#)
Status: **Active**
Overview: [DuraClik™ Connector System](#)
Description: DuraClik™ ISL Wire-to-Board Crimp Receptacle Terminal, Female, ASS 0.3 Square Wire, Gold

Documents:
[Drawing \(PDF\)](#) [Packaging Specification PK-560124-002 \(PDF\)](#)
[Application Specification AS-560123-001-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Crimp Terminals
Series [560124](#)
Application Signal
Crimp Quality Equipment Yes
Overview [DuraClik™ Connector System](#)
Product Name DuraClik™
UPC 889056303293

Physical
Gender Female
Material - Metal Copper Alloy
Material - Plating Mating Gold
Material - Plating Termination Tin
Net Weight 0.063/g
Packaging Type Reel
Plating min - Mating 0.203µm
Plating min - Termination 0.610µm
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 1.40mm
Wire Size AWG 22
Wire Size mm² 0.35

Electrical
Current - Maximum per Contact 3.0A
Voltage - Maximum 125V

Material Info

Reference - Drawing Numbers
Application Specification AS-560123-001-001
Packaging Specification PK-560124-002
Sales Drawing SD-560124-002

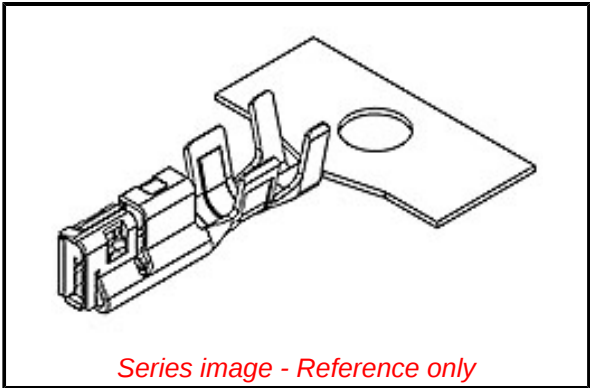

Series image - Reference only

EU ELV
Compliant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per
-ED/01/2017 (12
January 2017)
Halogen-Free
Status
Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS Not Relevant
ELV Compliant
RoHS Phthalates Not Contained

Search Parts in this Series
[560124](#) Series

Use With
[560123](#) DuraClik™ ISL Receptacle Housing

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION