

Pushbutton Ø 19 mm silver contact

82-5571.2000



<https://eao.com/p/82-5571.2000>

Your product:



82-5571.2000
Pushbutton Ø 19 mm silver contact

FRONT

Front bezel material:	Aluminium
Front bezel shape:	flush

MOUNTING

Mounting cut-out:	Ø 19 mm
--------------------------	---------

OPERATING-/INDICATION PART

Lens material:	Aluminium
Lens optics:	opaque
Lens shape:	convex
Lens colour:	Nature
Lens illumination:	non illuminative

ELECTRICAL CHARACTERISTICS

Electrical lifetime:	50 000 cycles of operation
Contacts:	1 C
Thermal current Ith:	5 A
Rated insulation voltage Ui:	250 V
Pollution degree:	2, according to EN IEC 60947-1
Switching voltage and switching current:	

according to IEC 60947-5-1 (Silver contacts)

Service categorie AC-15

Voltage	Current
24 VAC	1 A
35 VAC	1 A (M12 version)
110 VAC	1 A
220 VAC	0.5 A

Switch rating DC service categorie DC-13 (Silver contacts)

Voltage	Current
24 VDC	0.7 A
35 VDC	0.5 A (M12 version)
110 VDC	0.2 A
220 VDC	0.1 A

according to UL 508 (Silver contacts)

$\cos\phi$ 0,75 ... 0,8

Voltage	Current
120 VAC	5 A
240 VAC	3 A
24 VAC	1 A

Electric strength: 1500 VAC, 50 Hz 1 minute between life terminals and ground

Rated Operational Voltage Ue: 250 VAC

MECHANICAL CHARATERISTIC

Operating Travel: ca. 3 mm

Contact material: Silver

Switching action: Maintained

Weight: 0.019 kg

Operating force: 4 N ... 7 N

Terminal: Soldering terminal, 2.8 x 0.5 mm

Tightening torque: 0.5 ... 0.6 Nm

Switching system: Snap-action switching element

Mechanical lifetime: 500 000 cycles of operation

AMBIENT CONDITION

Climate resistance: Damp heat, 21 days according to IEC 60512-11

Operating temperature: - 30 °C ... + 70 °C

Storage temperature: - 40 °C ... + 80 °C

IP front protection: IP65, IP67

Vibration resistance: 10 ... 500 Hz, amplitude 1.5 mm p-p according to IEC 60068-2-6

Shock resistance: Max. 500 m / s² as per IEC 60068-2-27

CERTIFICATE


Approbations: CB, CCC, C UL, UL

Conformities: CE, 2011 / 65 / EC (RoHS), 2014 / 35 / EU (LVD)

OTHER


Short Description: Pushbutton Ø 19 mm silver contact, Maintained, 1 C, Soldering terminal, 2.8 x 0.5 mm, Aluminium, Nature

Dimension drawings:

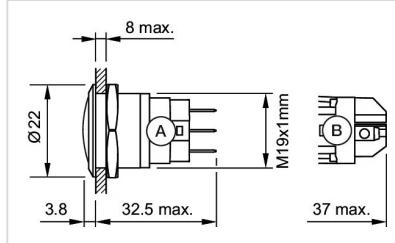


A = Solder terminal
B = Screw terminal

Mounting cut-outs:

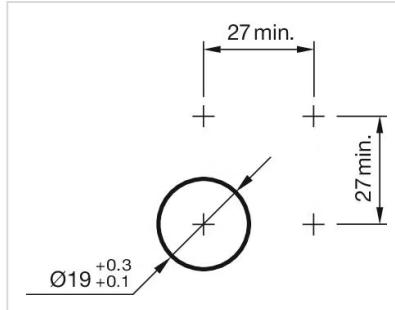

Wiring diagrams:

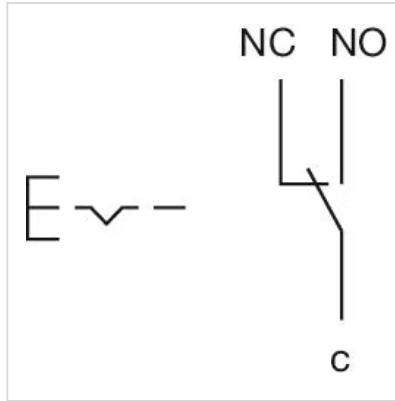

Component layouts:

