


Model 1469 Adapter – Binding Post To BNC Male, Four Terminal Isolation

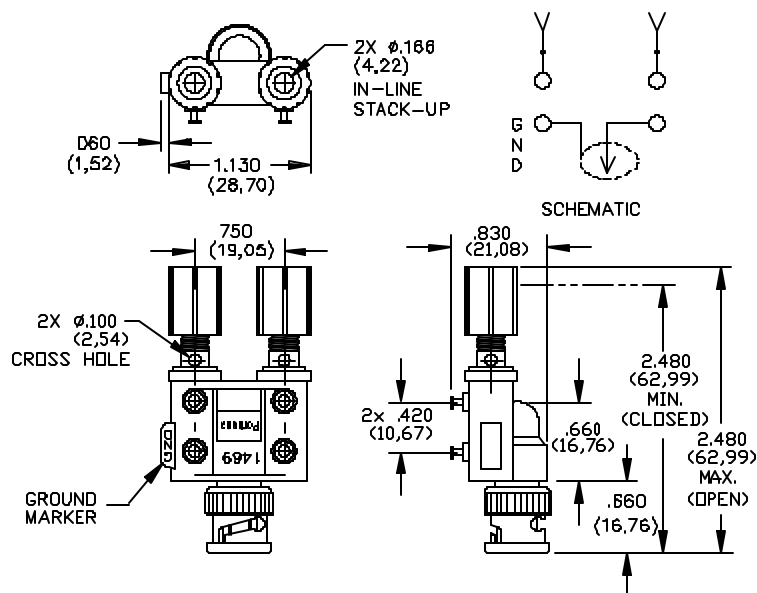

FEATURES:

- Permits single or double banana plugs to be used with equipment having BNC female
- Provides isolation for a four terminal network
- Binding posts facilitate connections of test leads or additional components
- Bright tin plated solder turret terminals provide permanent noise-free connections

MATERIALS:

Upper Conn: Binding Posts, Insulated

Material: Binding Post Body – Brass per QQ-B-626, Alloy 360, ½ Hard

Finish: Nickel plated per QQ-N-290, Class 2, 200/300 microinches

Insulation: Polycarbonate

Color: One red, one black

Insulation: Polypropylene molded to binding posts and BNC Male, Color: Black

Marking: “1469 POMONA”

Lower Conn: BNC Male

Finish: Body and Fittings – Tarnish resistant

Nominal Impedance: 50 Ohms

Center Contact – Gold plated per requirements of MIL-C-39012

Terminals:

Material: Brass per QQ-B-626, Alloy 360, ½ Hard

Finish: Bright tin plated per MIL-T-10727 Type I, 100/250 microinches

RATINGS:

Operating Temperature: +55° C. (+131° F.) Max.

Operating Voltage: Hand-held Testing:

30VAC/60VDC Max. Hands Free Testing in

Controlled Voltage Environments: 500 VRMS Max.

ORDERING INFORMATION: Model 1469