

Actuator

45-
2828.1D90.001



<https://eao.com/p/45-2828.1D90.001>

Your product:



45-2828.1D90.001 Actuator

FRONT

| | |
|-----------------------|-----------|
| Front dimension: | Ø 29,5 mm |
| Front bezel colour: | Black |
| Front bezel material: | Plastic |

MOUNTING

| | |
|---------|--------|
| Design: | raised |
|---------|--------|

OPERATING-/INDICATION PART

| | |
|-----------------|---------|
| Lever colour: | White |
| Lever shape: | long |
| Lever material: | plastic |

MECHANICAL CHARACTERISTIC

| | |
|----------------------|----------------------------|
| Weight: | 0.03 kg |
| Switching action: | Rest - Maintained |
| Switching positions: | 2 positions |
| Switching angle: | 90° right / -45° ... +45° |
| Mechanical lifetime: | 1 Mio. cycles of operation |
| Operating frequency: | 1 800/h |


AMBIENT CONDITION

| | |
|-------------------|--|
| Shock resistance: | According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms |
|-------------------|--|


| | |
|-------------------------------|---|
| IP front protection: | IP66, IP67, IP69K |
| Operating temperature: | – 25 °C ... + 70 °C |
| Storage temperature: | – 40 °C ... + 80 °C |
| Climate resistance: | During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6 |
| Vibration resistance: | According to IEC 60068-2-6: 10 ... 500 Hz: 5 g |

OTHER


| | |
|-----------------------------|---|
| Housing material: | Plastic |
| Hints: | External diameter of the long lever 44.8 mm |
| Short Description: | Actuator, Ø 29,5 mm, optional illuminative, White, long, Black, Plastic, Rest - Maintained, IP66, IP67, IP69K |
| Switching positions: | |

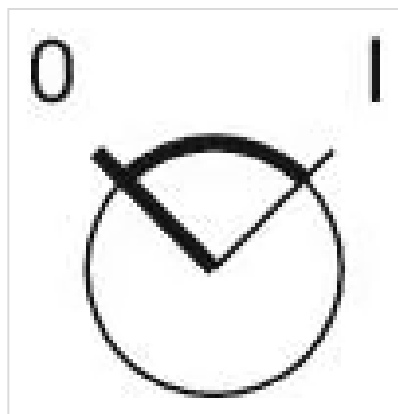

Dimension drawings:

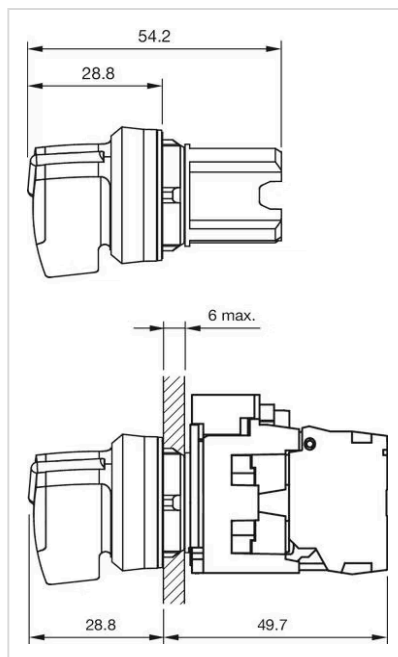

Mounting cut-outs:

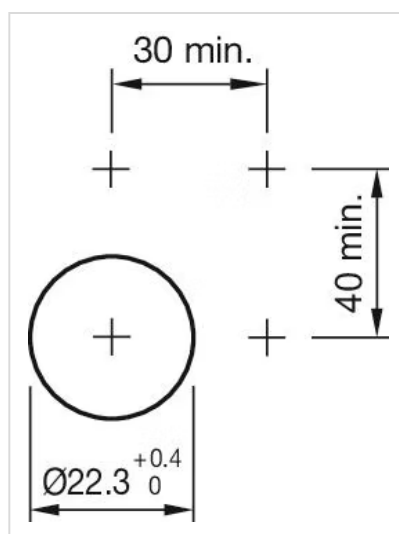

Wiring diagrams:

