


CSTSN6U

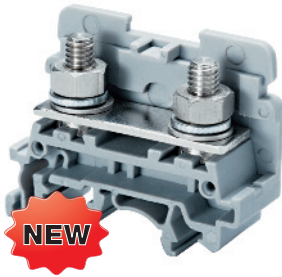

17 mm

39.5 x 50 mm

12 mm

Polyamide 6.6

2 screw connection
for M5 ring/fork lugs



22-2 AWG 1.5-35 sq.mm 22-2 AWG


600 V 1000 V 600 V

125 A 125 A 125 A

25 lb-in 3.0 Nm 25 lb-in



CSTSB4U

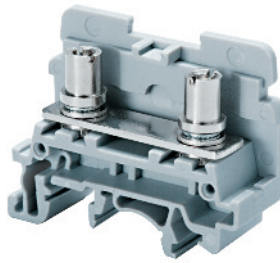

17 mm

39.5 x 50 mm

12 mm

Polyamide 6.6

2 screw connection
for M4 ring/fork lugs



22-6 AWG 1.5-10 sq.mm 22-6 AWG


600 V 1000 V 600 V

65 A 57 A 65 A

14 lb-in 1.2 Nm 14 lb-in



CSTSB5U

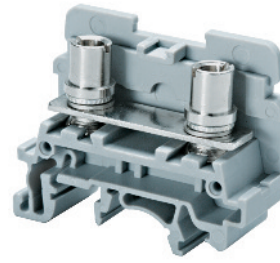

17 mm

39.5 x 50 mm

12 mm

Polyamide 6.6

2 screw connection
for M5 ring/fork lugs



22-4 AWG 1.5-16 sq.mm 22-4 AWG

600 V 1000 V 600 V

80 A 76 A 80 A

25 lb-in 2.0 Nm 25 lb-in



Cat. No.	Std. Pk.
CSTSN6U	100
EPCSTSN5U	50



CA702	50
CA802	50

CSTSPC1	100
CSTSPC1-1	100

CSTSPC1-2	10
CSTSPC1-3	10
CSTSPC1-4	10

CA514/1-2	100
CA514/1-3	50
CA514/1-4	50

CA514/3-2	100
CA514/3-3	50
CA514/3-4	50

MT2B4	100
-------	-----

Cat. No.	Std. Pk.
CSTSB4U	100
EPCSTN5U	50



CA702	50
CA802	50

CSTSPC1	100
CSTSPC1-1	100

CSTSPC1-2	10
CSTSPC1-3	10
CSTSPC1-4	10

CA514/1-2	100
CA514/1-3	50
CA514/1-4	50

CA514/3-2	100
CA514/3-3	50
CA514/3-4	50

MT2B4	100
-------	-----

Cat. No.	Std. Pk.
CSTSB5U	100
EPCSTN5U	50



CA702	50
CA802	50

CSTSPC1	100
CSTSPC1-1	100

CSTSPC1-2	10
CSTSPC1-3	10
CSTSPC1-4	10

CA514/1-2	100
CA514/1-3	50
CA514/1-4	50

CA514/3-2	100
CA514/3-3	50
CA514/3-4	50

MT2B4	100
-------	-----