

## SUMMARY

### # Wires



*Image is for illustrative purpose only*

Series	2B
Termination type	No contacts / Accessory
IP rating	0
AWG wire size	0.00 - 0.00
Cable Ø	7.00 - 7.70 mm
Status	active

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model	GMA*: Bend relief White
Keying	No keying
Housing Material	Thermoplastic polyurethane elastomer (Elastollan 1185 A)
Variant	B : White
Weight	1.95 g

### Performance

Configuration
Insulator
Rated Current


### Others

Temp (min / max): -40°C / +80°C

*LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.*

---

# DRAWINGS

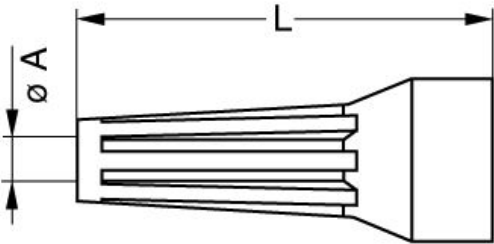

No keying

## Dimensions

	A	L
mm.	7.0	36
in.	0,28	1,42

---

# RECOMMENDED BY LEMO

## Tools

*LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.*