

Actuator

45-
2131.2160.000



<https://eao.com/p/45-2131.2160.000>

Your product:



45-2131.2160.000
Actuator

FRONT

Front dimension: Ø 29,5 mm
Front bezel colour: Silver
Front bezel material: Metal

MOUNTING

Design: raised

OPERATING-/INDICATION PART

Lens illumination: non illuminative
Lens colour: Blue
Lens shape: flush
Lens material: Plastic
Lens optics: opaque

MECHANICAL CHARACTERISTIC

Weight: 0.04 kg
Switching action: Momentary
Switching system: Slow-make switching element
Mechanical lifetime: 500 000 cycles of operation
Operating frequency: Max. 3 600/h


AMBIENT CONDITION

Vibration resistance:	According to IEC 60068-2-6: 20 ... 500 Hz: 5 g
IP front protection:	IP66, IP67, IP69K
Operating temperature:	- 25 °C ... + 70 °C
Storage temperature:	- 40 °C ... + 80 °C
Climate resistance:	During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6
Shock resistance:	According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms


OTHER

Housing colour:	Silver
Housing material:	Metal
Short Description:	Actuator, Ø 29,5 mm, flush, non illuminative, Blue, Plastic, opaque, Silver, Metal, Momentary, IP66, IP67, IP69K

Dimension drawings:

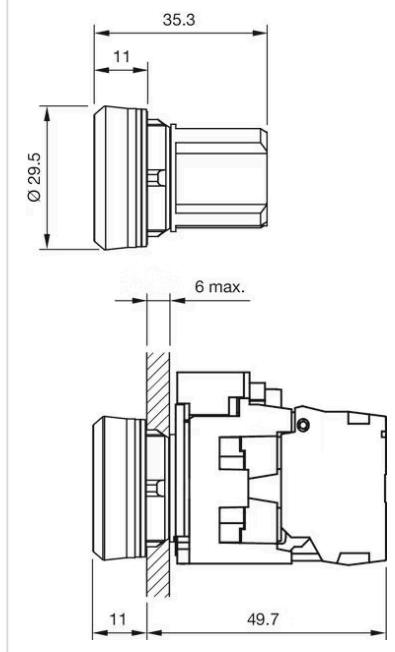

Wiring diagrams:

 

Mounting cut-outs:

