

SUMMARY

Wires

High voltage	1
--------------	---



Image is for illustrative purpose only

Series	3Y
Termination type	Male solder High-Voltage
IP rating	50
AWG wire size	0.00 - 0.00
Cable Ø	7.10 - 8.00 mm
Status	active

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model	FFA*: Straight plug with cable collet
Keying	Circular
Housing Material	
Weight	98.53 g

Performance

Configuration	3Y.430 : 1 High Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated Current	15 Amps


Specifications

Contact Type: Solder	
Test voltage (kV DC)(value for male contact plug mated with female contact socket)	42
Test voltage (kV AC)	29
Creepage distance min.:	58 mm

Others

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

DRAWINGS

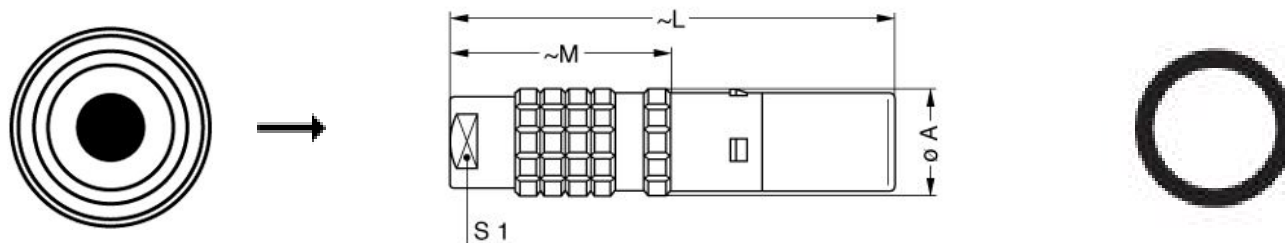

RECOMMENDED BY LEMO

Tools

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.