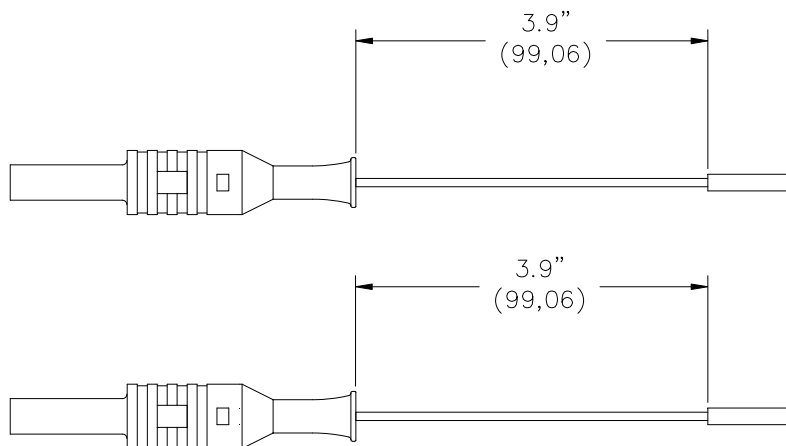


Model 72936**2mm Sheathed Banana Plug to 4mm Sheathed Banana Plug****Features**

- Provides a quick and easy configuration between a 4mm sheathed banana jack to a 2mm sheathed banana jack.

Materials

2mm/4mm Banana Plugs:

Body: Nickel Plated Brass

Spring: Nickel Plated Beryllium Copper

Plug Insulation: Polypropylene, color per part number

Wire Insulation: PVC, color per part number

Ratings

Operating Voltage: For *CE Compliance* and for personal safety, do not hold in hand when voltages exceed 33 Vac/70 Vdc.

Do not use on circuits where transient stresses can exceed the rated voltage.

Operating Temperature: -20°C to +80°C (-4°F to +176°F) Max.

Operating Current: 2 Amperes Max.

Ordering Information

Model: 72936-XX-*

XX = Standard Length: 39 (3.9in) (10cm)

* = Standard Color: -0 Black, -2 Red

Ordering Example: 72936-39-2, Test Lead is 3.9in and Red.

USA: Sales: 800-490-2361
Technical Support: technicalsupport@pomonatest.com
Fax: 425-446-5844

Europe: 31-(0) 40 2675 150 **International:** 425-446-5500

Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = $\pm .02$ " (.51 mm), .xxx = $\pm .005$ " (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.