


TSSOP-48 (long pins) to DIP-48 SMT Adapter  
(0.5 mm pitch, 12.5 x 6.1 mm body)


| REF. | DIMENSIONS |      |      |        |       |      |
|------|------------|------|------|--------|-------|------|
|      | mm         |      |      | inches |       |      |
|      | MIN.       | TYP. | MAX. | MIN.   | TYP.  | MAX. |
| A    |            | 6.10 |      |        |       |      |
| B    |            | 1.60 |      |        |       |      |
| C    |            | 0.30 |      |        |       |      |
| D    |            | 0.20 |      |        |       |      |
| E    |            | 0.50 |      |        |       |      |
| F    |            |      |      |        | 0.600 |      |
| G    |            |      |      |        | 0.100 |      |
| H    |            |      |      |        | 0.025 |      |

Top View (SMT Footprint)

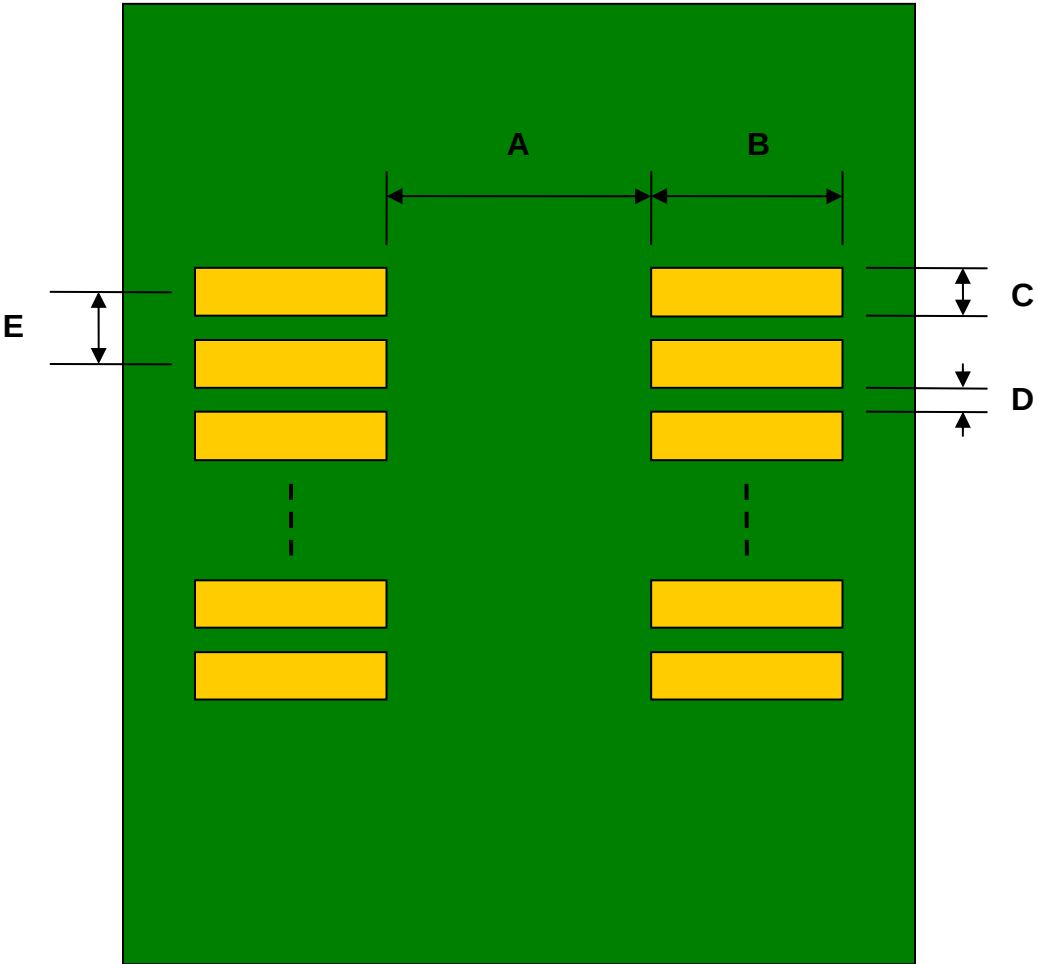


(Representative drawing only - not to scale)

**Bottom View (DIP Pins)**

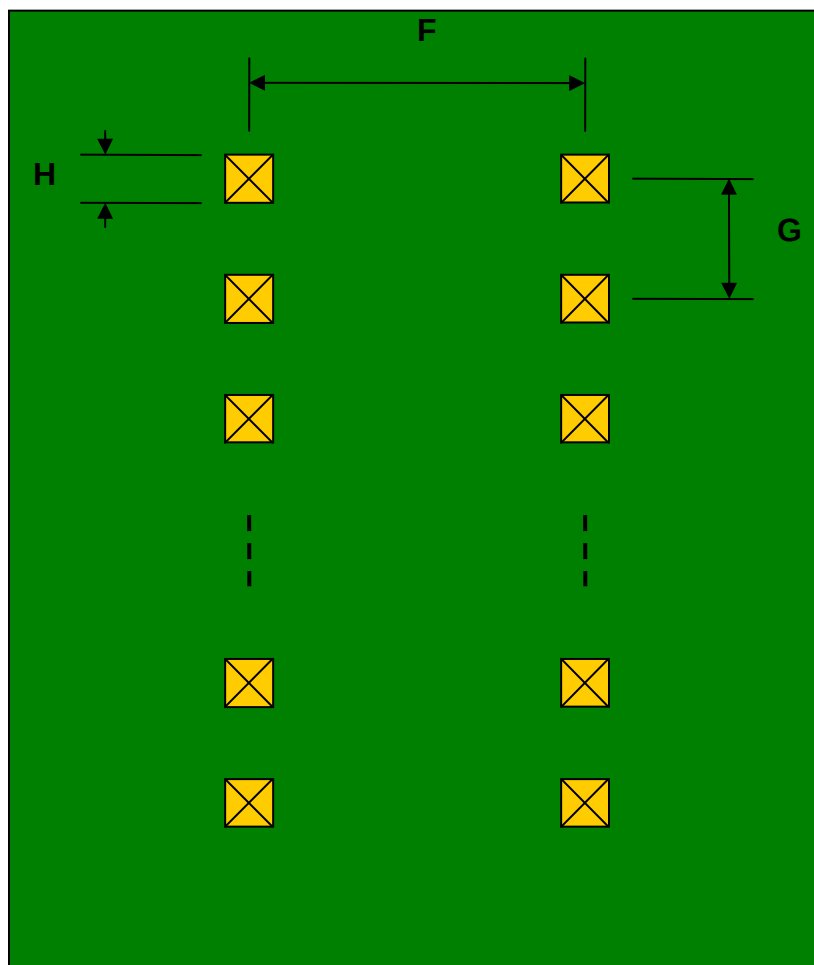

(Representative drawing only - not to scale)

**Side View (DIP Pins)**

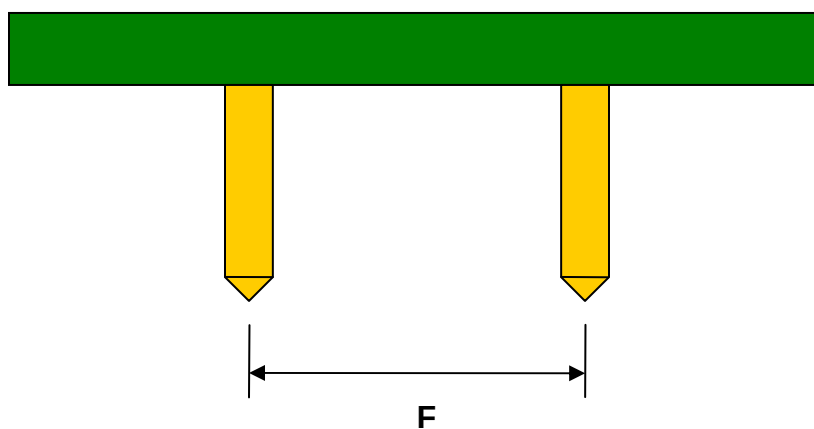

(Representative drawing only - not to scale)