

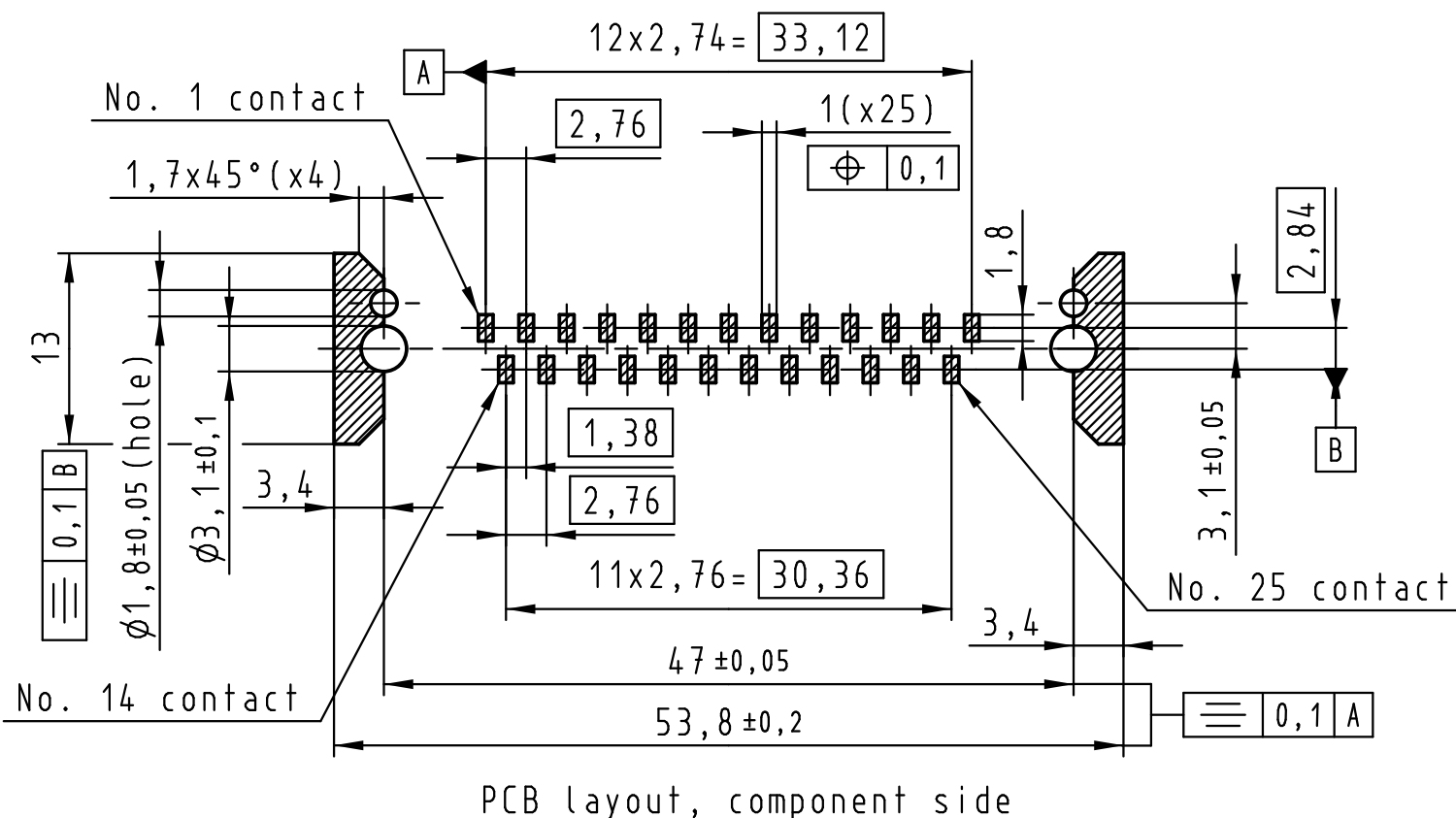
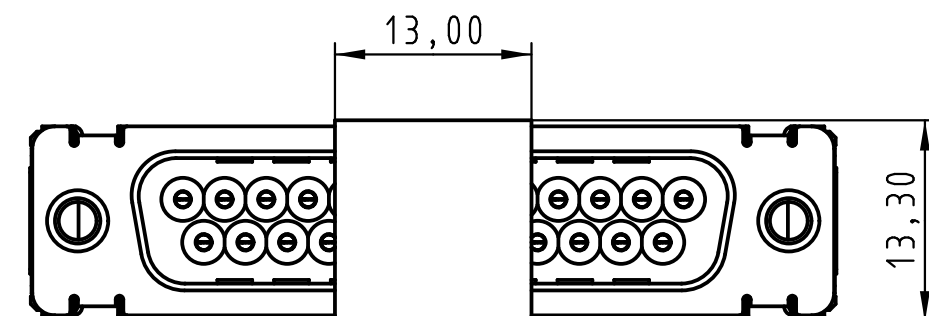
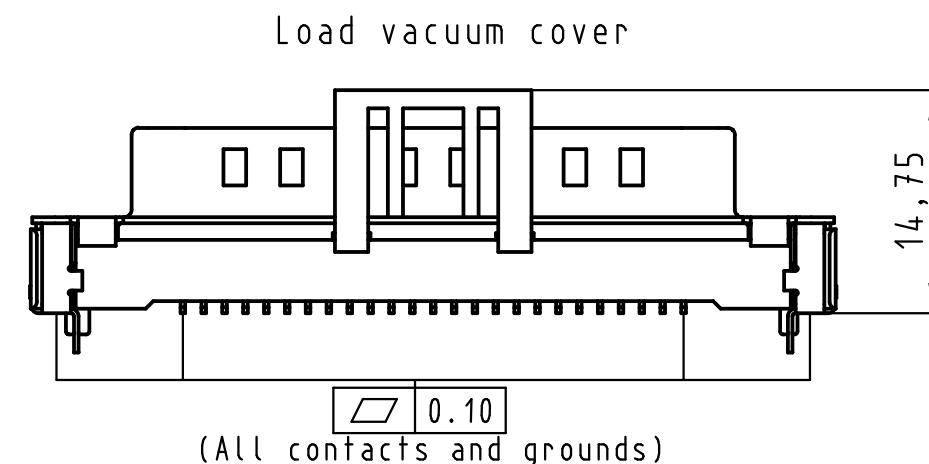
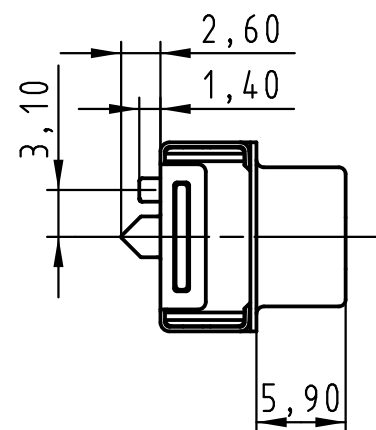
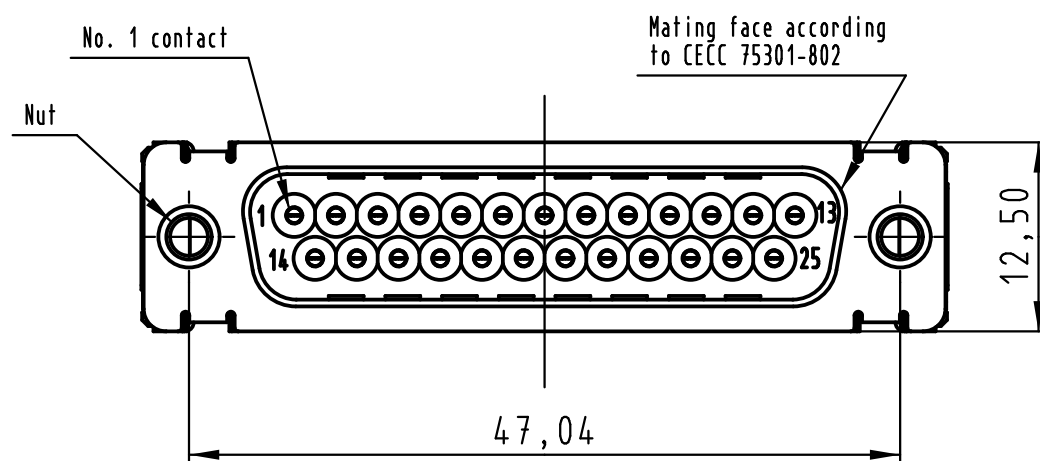



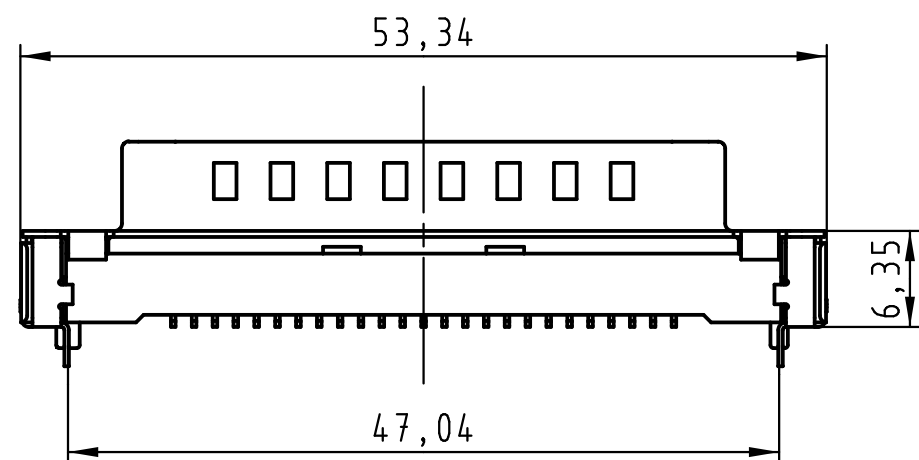


Max. Temperature: 260° during 10 seconds.


0955 369 3811 741	1	M3	Black insulator	Reel Packaging: 140 connectors (See details on page2/2)				
0955 369 3812 741	1	4-40 UNC						
0955 369 6811 741	2	M3						
0955 369 6812 741	2	4-40 UNC						
0955 369 7811 741	3	M3						
0955 369 7812 741	3	4-40 UNC						
Part number	PL	Nut	Index designation					
 All Dimensions in mm Original Size DIN A 3			Techn. Character.		Free size tolerances			
					D-Sub SMT, 25 poles Male, Straight with nuts and ground pins	2 : 1		
			Detail.	25-Oct-11			Johnson.S	
			Insp.	17-Nov-11			Steven.W	
			Stand.	17-Nov-11			Steven.W	
EC04070	17-Nov-11	Johnson.S	Zhuhai HARTING Limited			TB 09 55 369 x81x		Page 1 / 2
Mod.	Dat.	Name				Sub.		

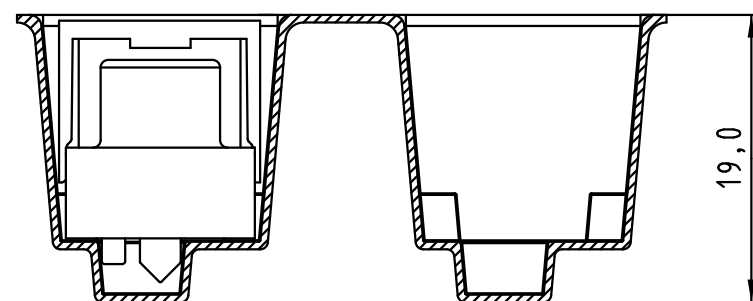

Detail A

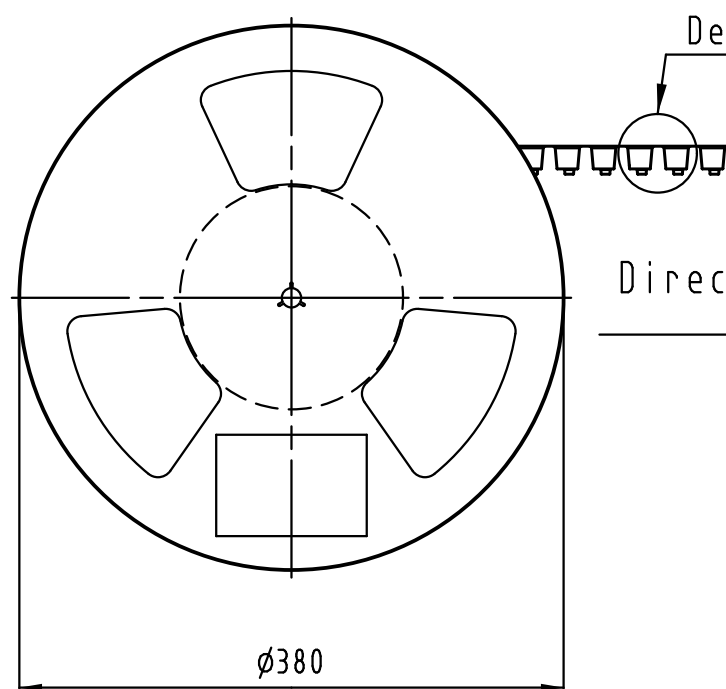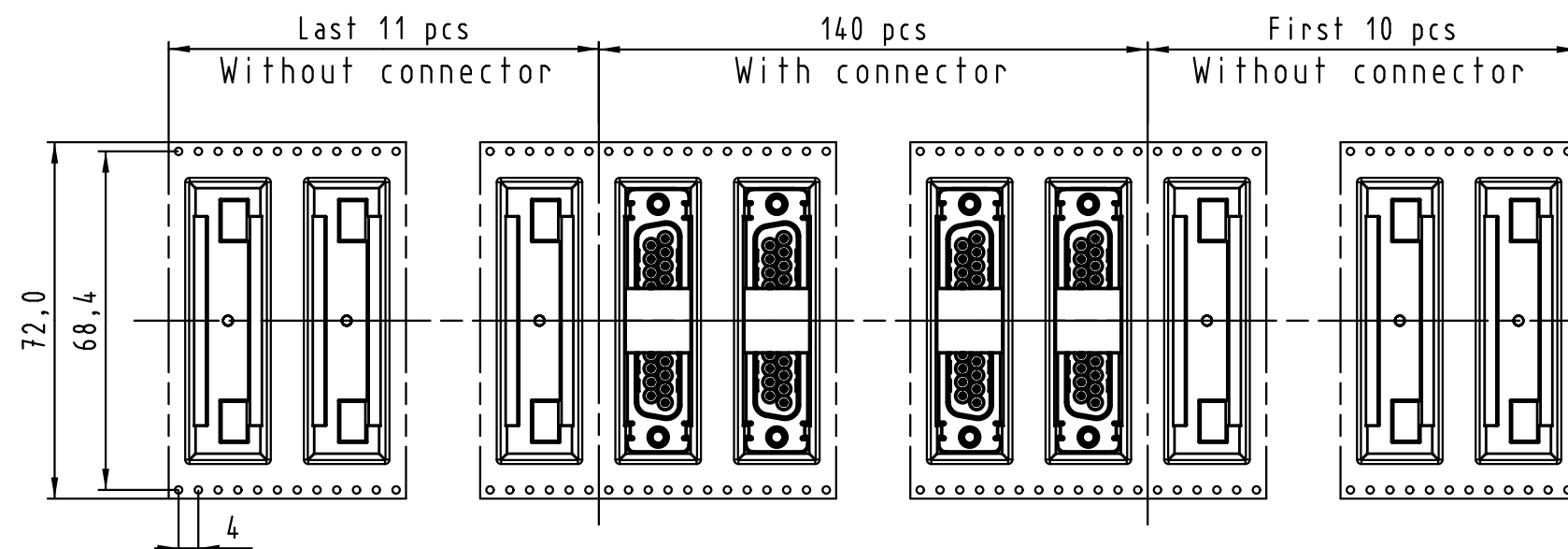

Direction of unreeling

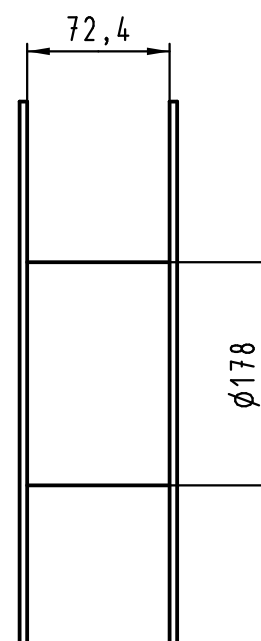

See TB 09 55 369 x81x folio 1/2
for connector dimensions
and PCB layout

Packaging in accordance with
EIA 481-2.

0955 369 3811 741	1	M3	Black insulator	Reel Packaging: 140 connectors
0955 369 3812 741	1	4-40 UNC		
0955 369 6811 741	2	M3		
0955 369 6812 741	2	4-40 UNC		
0955 369 7811 741	3	M3		
0955 369 7812 741	3	4-40 UNC		
Part number	PL	Nut	Index designation	

 All Dimensions in mm Original Size DIN A 3	Techn. Character.				Free size tolerances	
					D-Sub SMT, 25 poles Male, Straight with nuts and ground pins	
					TB 09 55 369 x81x	
EC04070	17-Nov-11	Johnson.S	Zhuhai HARTING Limited			Page 2/2
Mod.	Dat.	Name				