

SUMMARY

Wires

Low	10
High	0
Coax	2
Triax	0
Quad	0
Fiber	0
Fluidic	0

 


Image is for illustrative purpose only

Series	3B
Termination type	Male solder Mixed coaxial /
IP rating	50
Cable Ø	0.00 - 6.00 mm
Matching parts	EGG.3B.850.CLL1
Status	active
Alternative part	

Download

[Request a quote](#)

[Catalog](#)

[See video assembly instructions](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model	FG*: Straight plug, cable collet and nut for fitting a bend relief
Keying	1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Housing Material	Brass (chrome plated) shell and collet nut, nickel plated brass latch sleeve and mid pieces
Cable Fixing	D61: 0 - 6 mm
Variant	Z : Nut for fitting a bend relief
Weight	49.97 g

Performance

Configuration	3B.850 : 2 Coax (50 Ohm), 10 Low V.
Insulator	L: PEEK (UL 94 / V-0/3.2, depends on material thickness)
Rated Current	8 Amps

Specifications

Contact Type: Coaxial 50 Ohm (Crimp) Type C
Max. Matings: 5000

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Contact Dia.: 0.7 mm (0.03in)

R (max): 5.8 mOhm

Test voltage (kV rms): 0.75

Test voltage (kV dc): 1.05

Others

Temp (min / max): -55°C / +250°C

Humidity (max): <=95% [at 60 deg C /140 F]

Vibration: 15 g [10 Hz - 2000 Hz]

Shock Resistance: 100 g [6 ms]

Salt Spray Corrosion: >1000 hr

Climatical Category: 50/175/21



Shielding (min): 75 dB (10 MHz)

Shielding (min): 40 dB (1 GHz)

IP Rating: 50

DRAWINGS

Draws

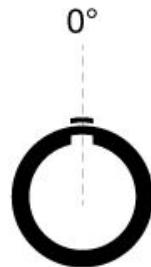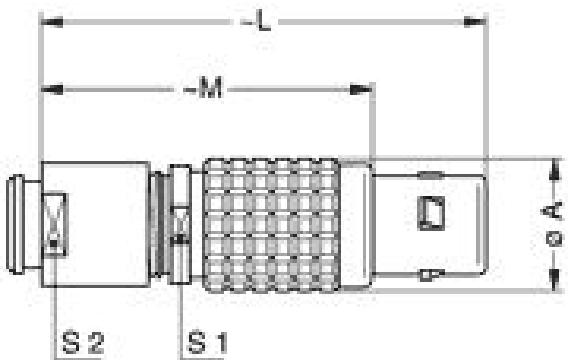

Dimensions

	A	L	M	S1	S2
mm.	18	56.5	41.5	15	15
in.	0,71	2,22	1,63	0,59	0,59

RECOMMENDED BY LEMO

Tools

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Extractor: DCC.91.384.5LA

Coax Tool: -

Die Tool: DPE.99.103.8K

Spanner wrench: DCD.3B.040.PA150

Caps: BFG.3B.100.PCSG

Cables

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.