


QFN-36 to DIP-40 SMT Adapter (0.5 mm pitch, 5.0 x 6.0 body, 3.45x4.57 split pad)


REF.	DIMENSIONS					
	mm			inches		
	MIN.	TYP.	MAX.	MIN.	TYP.	MAX.
A		4.10				
A2		5.10				
B		0.70				
C		0.25				
B2		3.45				
C2		4.57				
C3		2.54				
C4		1.52				
D		0.25				
D2		0.325				
E		0.50				
F					0.600	
G					0.100	
H					0.025	

Top View (SMT Footprint)

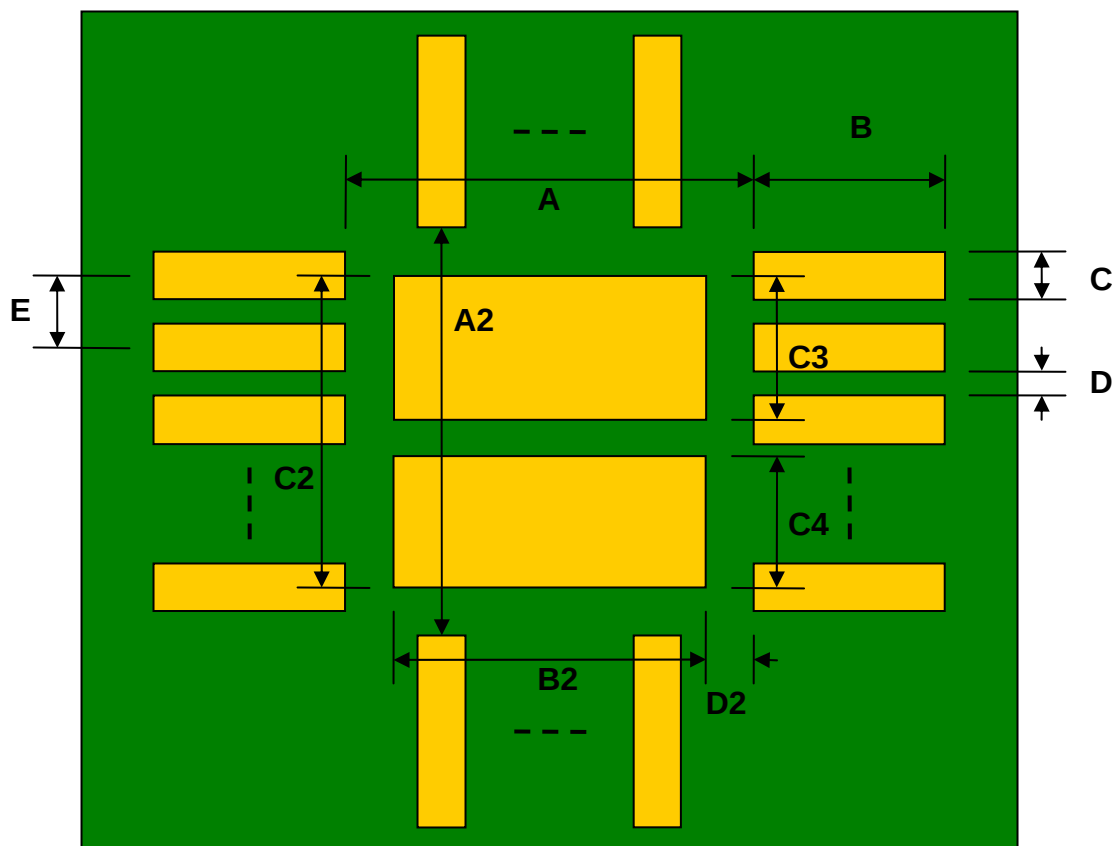


(Representative drawing only - not to scale)

Bottom View (DIP Pins)

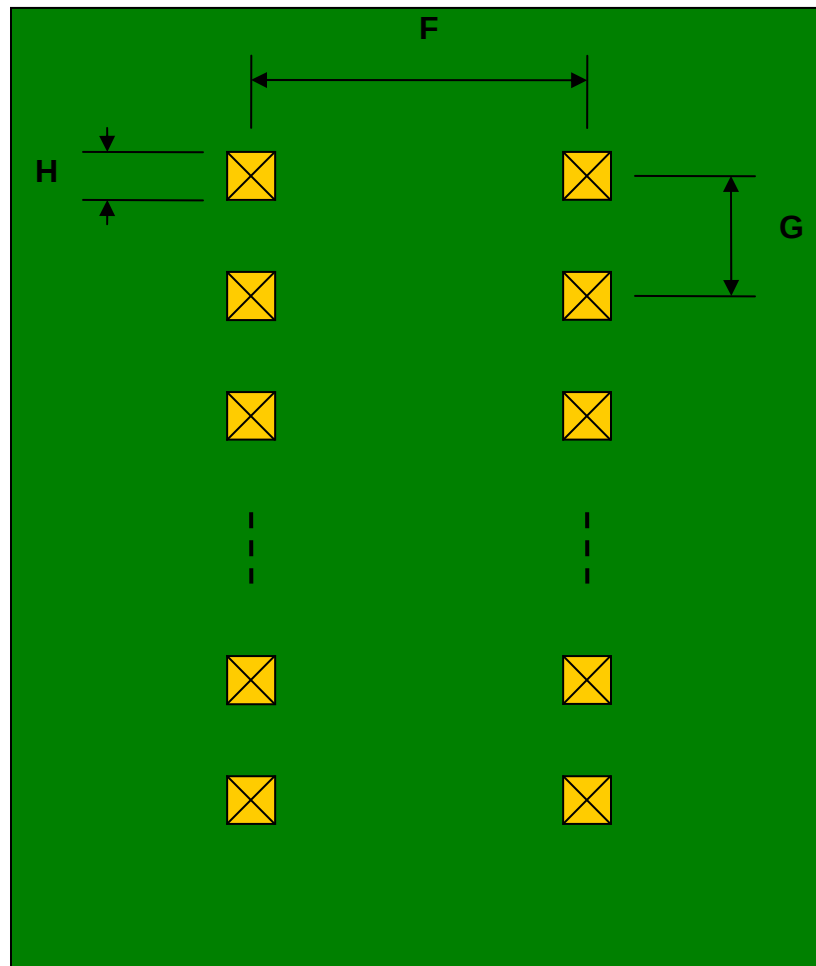

(Representative drawing only - not to scale)

Side View (DIP Pins)

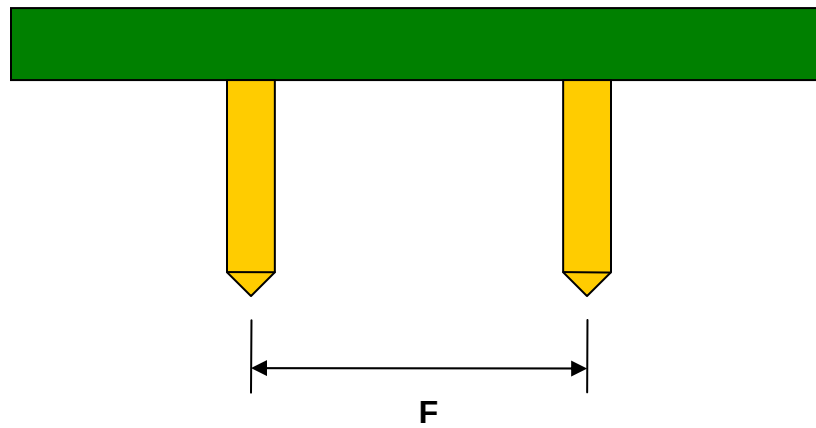

(Representative drawing only - not to scale)