

Actuator

704.095.018



<https://eao.com/p/704.095.018>

Your product:



704.095.018 Actuator

FRONT

Front dimension:	Ø 35 mm
Front bezel colour:	Nature
Front bezel material:	Aluminium

MOUNTING

Design:	flush
---------	-------

OPERATING-/INDICATION PART

Lever shape:	long
Lever material:	plastic
Lever colour:	Black

ELECTRICAL CHARACTERISTICS

Standards:	The switches comply with the "Standards for low-voltage switching devices" DIN EN 60947-1
------------	---

MECHANICAL CHARACTERISTIC

Mechanical lifetime:	≤2.5 Mio. cycles of operation
Switching positions:	3 positions
Switching action:	Momentary - Rest - Momentary
Weight:	0.056 kg
Switching angle:	42° left / 42° right

AMBIENT CONDITION

Storage temperature: – 40 °C ... + 85 °C

Operating temperature: – 40 °C ... + 55 °C

IP Protection: IP65 front side


OTHER

Short Description: Actuator, Ø 35 mm, non illuminative, Black, long, Nature, Aluminium, anodised, Momentary - Rest - Momentary


Hints: Max. 3 switching elements can be clipped on

max. number of switching elements: 3


Dimension drawings:

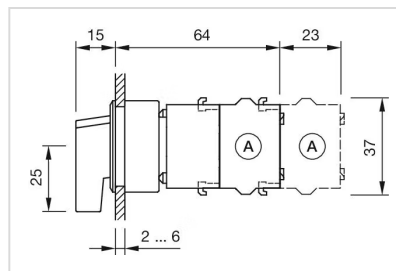

Switching positions:

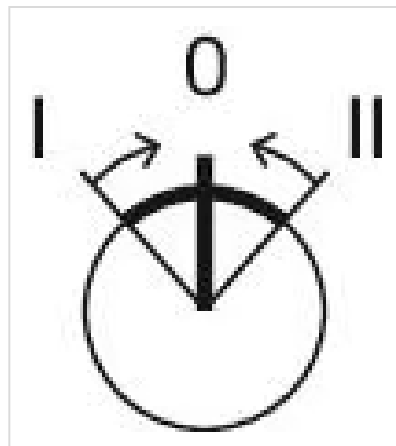

Mounting cut-outs:

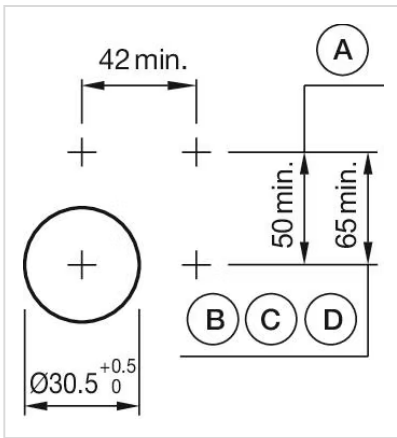

Wiring diagrams:

