

## SUMMARY

### # Wires

High voltage 8



*Image is for illustrative purpose only*

Series	2P
Termination type	Male solder
IP rating	50
AWG wire size	0.00 - 0.00
Cable Ø	3.20 - 5.20 mm
Status	active

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model CA\*: Straight plug with cable collet

### Keying

Housing Material PSU (Polysulfone), gray

Weight 9.06 g

### Performance

Configuration 2P.H08 : 8 High Voltage

### Insulator

Rated Current 6.5 Amps

### Specifications

Test voltage contact-contact : 10.3 kV rms

Air clearance min.: 7.42 mm

Creepage distance min.: 7.42 mm


### Others

Temp (min / max): -50°C / +150°C

R leak (He) (max): 0.0000001 mbar\*l/s (if vacuum-tested)

*LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.*

## DRAWINGS

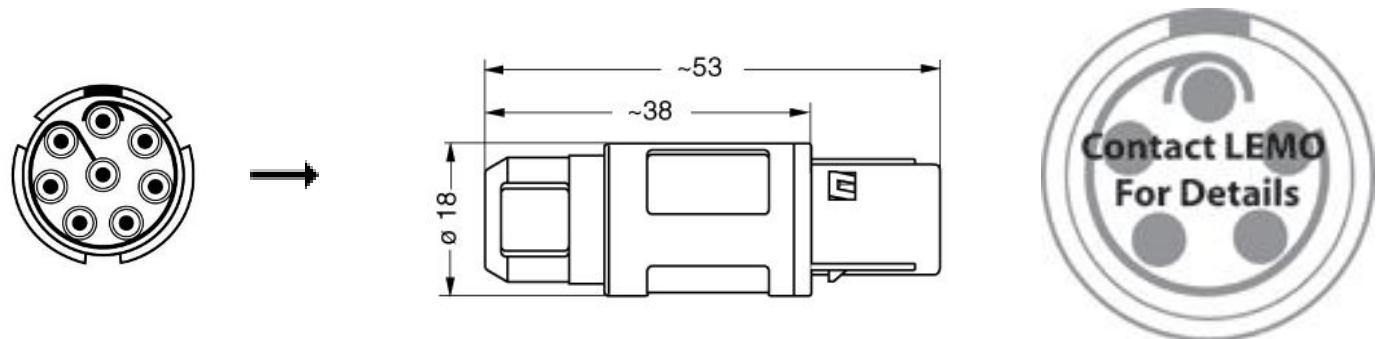

## RECOMMENDED BY LEMO

### Tools

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.