

# Actuator

45-  
2134.2120.000



<https://eao.com/p/45-2134.2120.000>

Your product:

---



## 45-2134.2120.000 Actuator

### FRONT

Front dimension:	Ø 29,5 mm
Front bezel colour:	Silver
Front bezel material:	Metal

### MOUNTING

Design:	raised
---------	--------

### OPERATING-/INDICATION PART

Lens illumination:	non illuminative
Lens colour:	Red
Lens shape:	flush
Lens material:	Plastic
Lens optics:	opaque

### MECHANICAL CHARACTERISTIC

Weight:	0.036 kg
Switching action:	Maintained
Switching system:	Slow-make switching element
Mechanical lifetime:	10 Mio. cycles of operation


### AMBIENT CONDITION

IP front protection:	IP66, IP67, IP69K
----------------------	-------------------


<b>Operating temperature:</b>	– 25 °C ... + 70 °C
<b>Storage temperature:</b>	– 40 °C ... + 80 °C
<b>Climate resistance:</b>	During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6
<b>Shock resistance:</b>	According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms
<b>Vibration resistance:</b>	According to IEC 60068-2-6: 20 ... 500 Hz: 5 g

## OTHER

<b>Housing colour:</b>	Silver
<b>Housing material:</b>	Metal
<b>Short Description:</b>	Actuator, Ø 29,5 mm, flush, non illuminative, Red, Plastic, opaque, Silver, Metal, Maintained, IP66, IP67, IP69K
<b>Hints:</b>	Push to unlatch
<b>Mounting cut-outs:</b>	

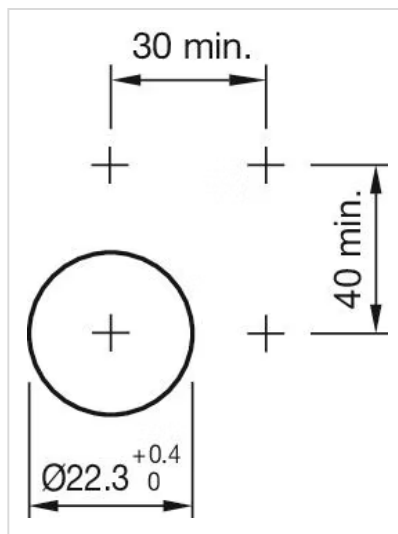

## Wiring diagrams:

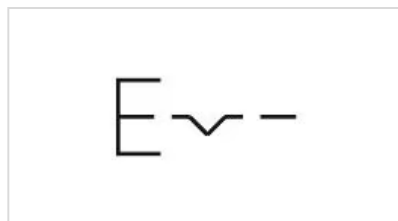

## Dimension drawings:

