

## RAFIX 16 - Pushbutton, non-illuminated, flush lens, square collar, alignable without gaps

**1.30.070.451/0500**

Legending available on request.



### General information

|                |                  |
|----------------|------------------|
| Actuator       | flat lens        |
| Color of lens  | opaque green     |
| Form of collar | square alignable |

### Dimensions

|                   |                  |
|-------------------|------------------|
| Collar dimensions | 24.95 x 24.95 mm |
| Collar dimensions | 24.95 x 24.95 mm |
| Overall height    | 7.15 mm          |
| Mounting depth    | 44.7 mm          |
| Mounting hole     | 16.2 mm          |
| Key grid          | 25 x 25 mm       |

### Mechanical design

|                     |                            |
|---------------------|----------------------------|
| Mounting            | ring nut, max. 1.2 Nm      |
| Contact function    | according to contact block |
| Contact arrangement | according to contact block |
| Illumination        | no                         |



### Mechanical characteristics

|                  |       |
|------------------|-------|
| Operating travel | 3 mm  |
| Robustness max.  | 100 N |

### Other specifications

|                                                 |                                          |
|-------------------------------------------------|------------------------------------------|
| Operating life (operations)                     | 2,000,000 cycle                          |
| Degree of protection from front side            | IP65 (DIN EN 60529)                      |
| Operation temperature min.                      | -25 °C                                   |
| Ambient temp. operating max. without lamp / LED | +70 °C                                   |
| Ambient temp. operating max. with lamp / LED    | +55 °C                                   |
| Storage temperature min.                        | -40 °C                                   |
| Storage temperature max.                        | +85 °C                                   |
| Environmental resistance                        | acc. to IEC 60068-2-14, -30, -33 and -78 |
| ROHS compliant                                  | yes                                      |
| REACH compliant                                 | yes                                      |

## Panel cut-out

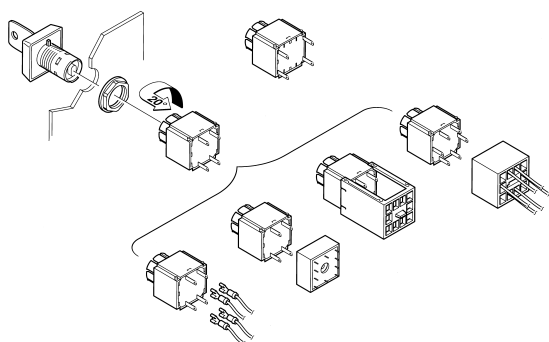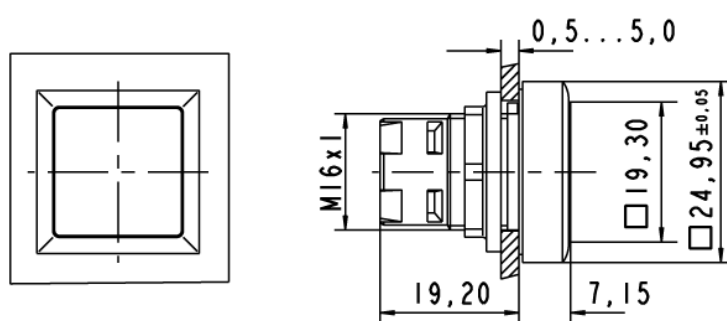

Technical data are approximate and intended solely for general orientation in the selection of a product.  
Subject to modifications and errors. Images and other graphics may only be similar.  
For more information, refer to [www.rafi.de](http://www.rafi.de) chapter Imprint / Data Protection.