


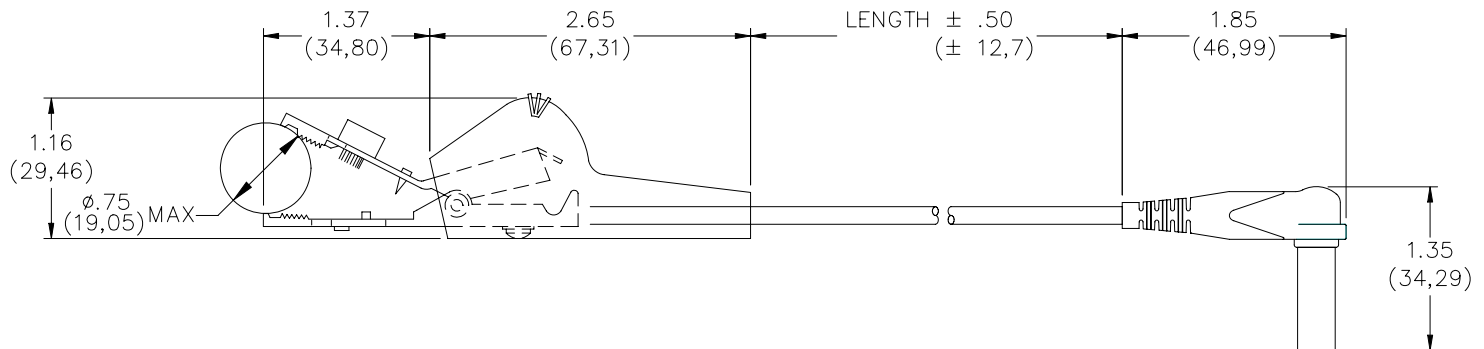

FEATURES:

- Multi-purpose test clips allow five ways to connect to a device under test
 - U-shaped nose for blade shaped terminals
 - Notched jaw for gripping screw heads, bare wire or terminals
 - Serrated teeth for gripping threaded or wire wrapped terminals
 - Cluster of sharp needles for piercing small gauge wires (#22-28 AWG)
 - Large piercing needle for penetrating large gauge wires

MATERIALS:

Jaws: Non-rusting Nickel Copper Alloy

Boot: Vinyl

Wire: 18 AWG , Silicone, 0.144" outside diameter

Banana Plug:

Spring: Beryllium Copper, nickel plated

Body: Brass Nickel Plated

Insulation: Polypropylene

RATINGS:

Operating Voltage: Hand-held 30 VAC/60 VDC

Hands free operation in a controlled voltage environment: 300 VRMS

Current: 8 Amperes

ORDERING INFORMATION: Model 6483-48-*

*=Color; 0-Black, 2-Red, -02 set (1 Black and 1 red lead)

Standard Length = 48" (1219,0)

All dimensions are in inches. Tolerances (except noted): .xx = ± 0.02 " (.51 mm), .xxx = ± 0.005 " (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies. Made in USA