


IPC0078C *Proto Advantage*


Datasheet revision 1.0

www.Proto-Advantage.com

MSOP-12 to DIP-16 SMT Adapter (0.65 mm pitch, 4.0 x 3.0 mm body) *Compact Series*

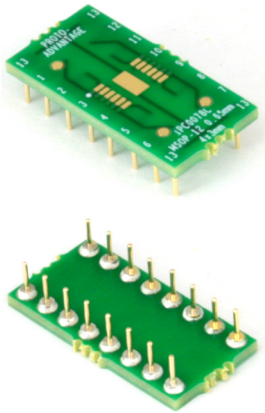


REF.	DIMENSIONS					
	mm			inches		
	MIN.	TYP.	MAX.	MIN.	TYP.	MAX.
A		3.40				
B		1.00				
C		0.42				
B2		1.60				
C2		3.00				
D		0.23				
D2		0.90				
E		0.65				
F					0.300	
G					0.100	
H		0.46				
X					0.400	
Y					0.800	

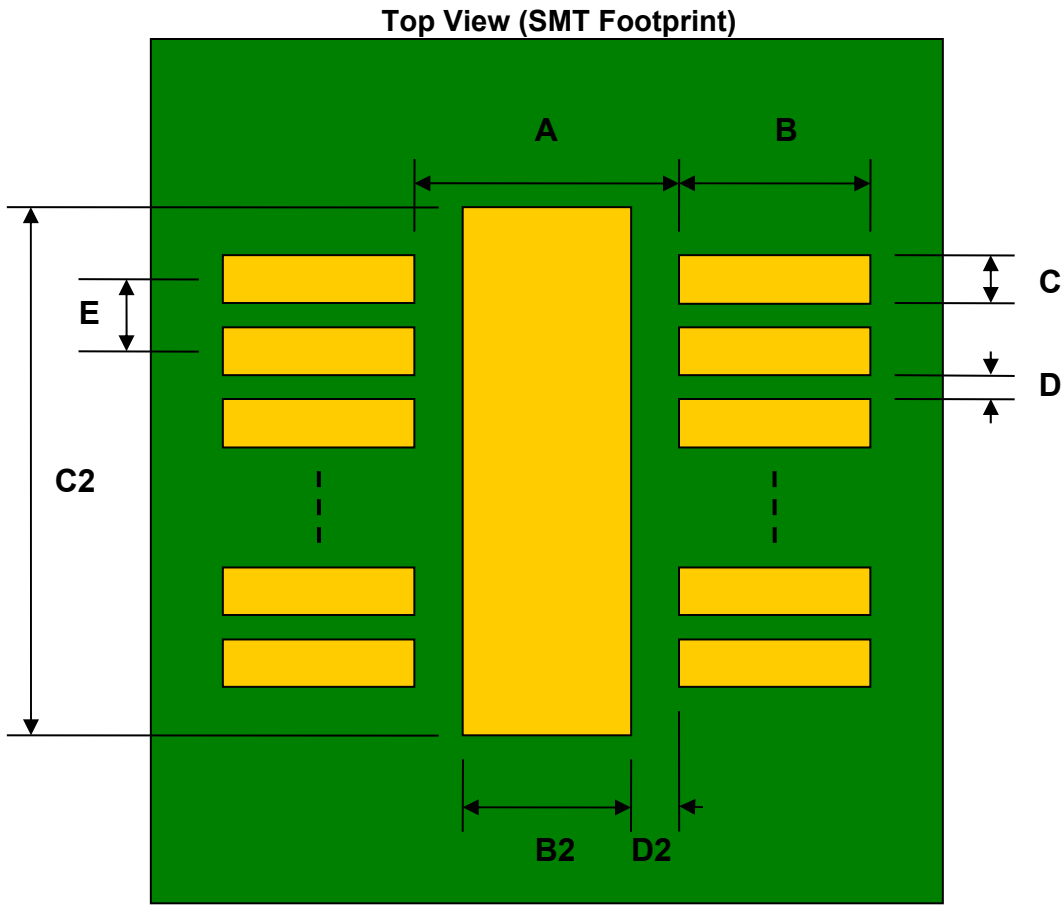


(Representative drawing only - not to scale)

Bottom View (DIP Pins)

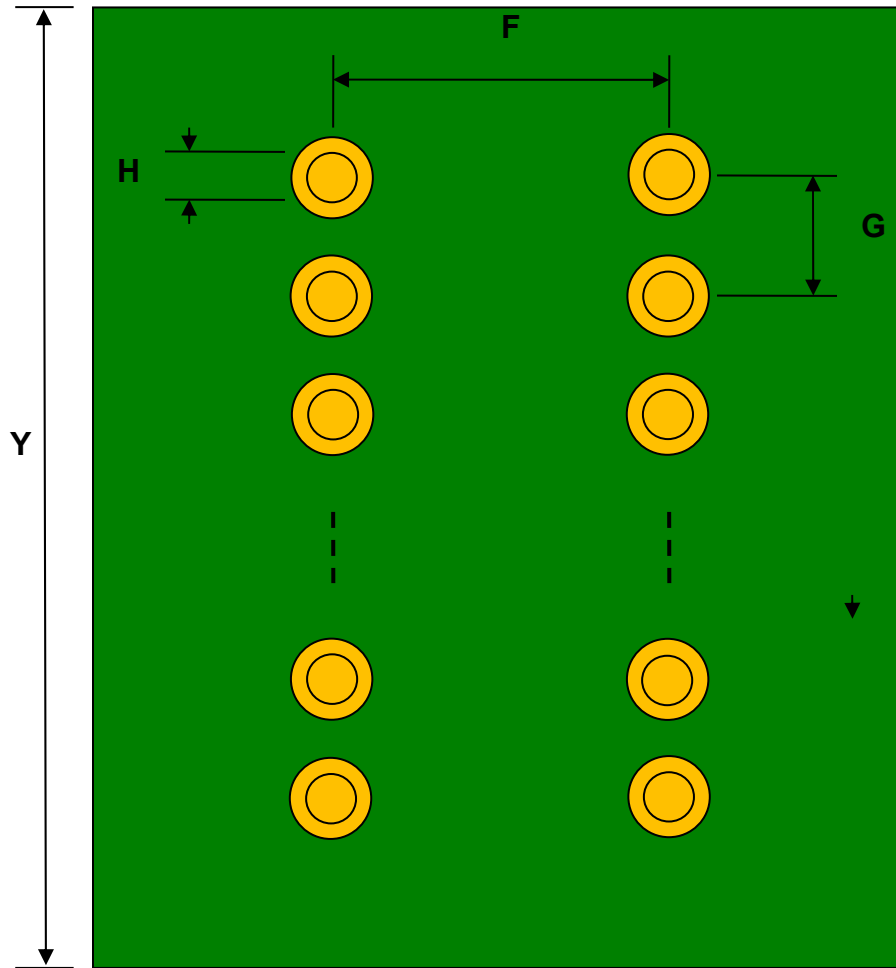

(Representative drawing only - not to scale)

Side View (DIP Pins)

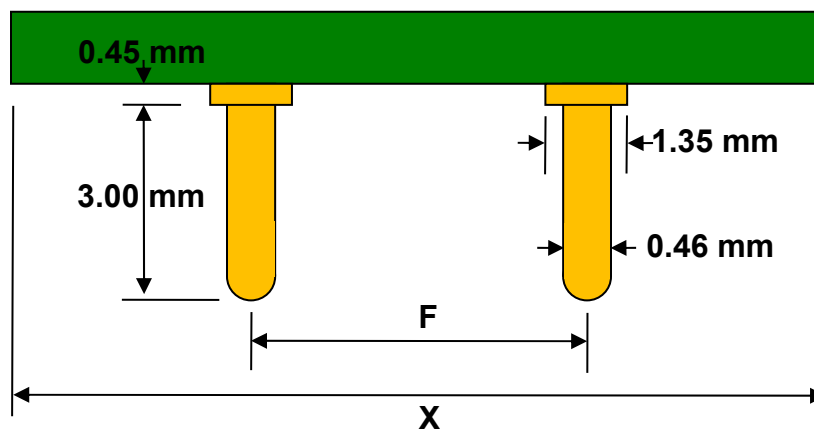

(Representative drawing only - not to scale)