


890-012 and 890-013 Right Angle Mount PCB, Single Row Nano Connector Surface Mount Type

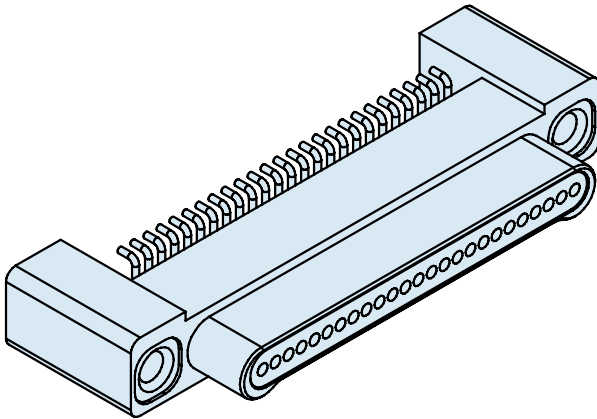

Right Angle SMT PCB Nano Connectors feature gold alloy TwistPin contacts. These nanominiature connectors offer premium performance and reliability for demanding applications. Available with #0-80 female threads.

Pre-Tinned PC Tails are coated with Sn63Pb37 tin-lead for excellent solderability.

Choose Aluminum, Titanium or Stainless Steel Shells in eight layouts from 5 to 51 contacts. Complies to the requirements of MIL-DTL-32139. These connectors are interchangeable with any corresponding Glenair Series 890 single row metal shell nanominiature connector.

How to Order Right Angle SMT PCB Connectors

Sample Part Number		890-012	-51P	T	-BRS	T
Series	890-012 Plug, Pin Contacts, Single Row, Right Angle SMT Nanominiature 890-013 Receptacle, Socket Contacts, Single Row, Right Angle SMT Nanominiature					
Insert Arrangement/ Contact Type	Plugs (890-012): 5P, 9P, 15P, 21P, 25P, 31P, 37P, 51P, Receptacles (890-013): 5S, 9S, 15S, 21S, 25S, 31S, 37S, 51S					
Shell Material and Finish	A1 - Aluminum Shell, Cadmium Plating A2 - Aluminum Shell, Electroless Nickel Plating T - Titanium Shell, Unplated S - Stainless Steel Shell, Passivated					
Termination Type	BRS - Board Right Angle Surface Mount					
Hardware	T - Female Thread, #0-80					


Dimensions in inches (millimeters) and are subject to change without notice.




890-012 and 890-013 Right Angle Mount PCB, Single Row Nano Connector Surface Mount Type

Single Row Nano Right Angle SMT Dimensions

890-012 Plug (Pin) Connectors

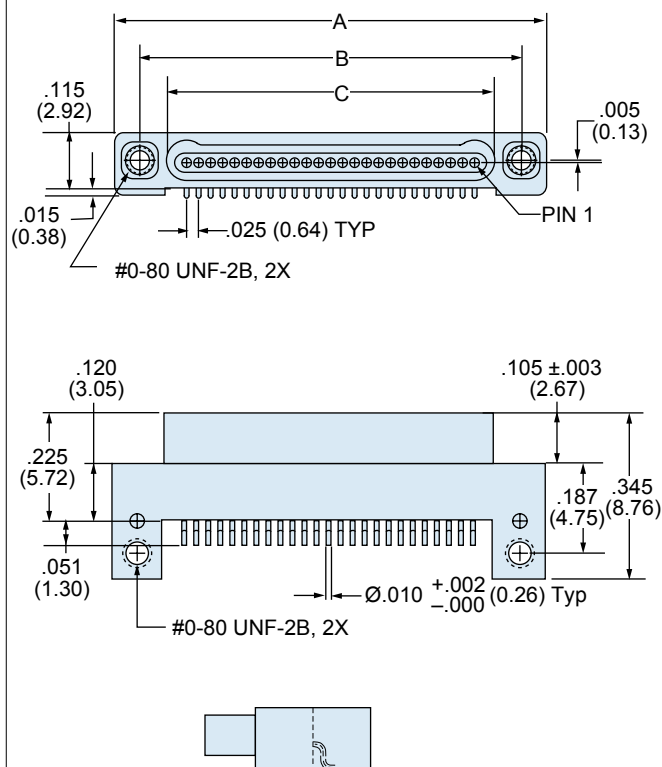

890-013 Receptacle (Socket) Connectors

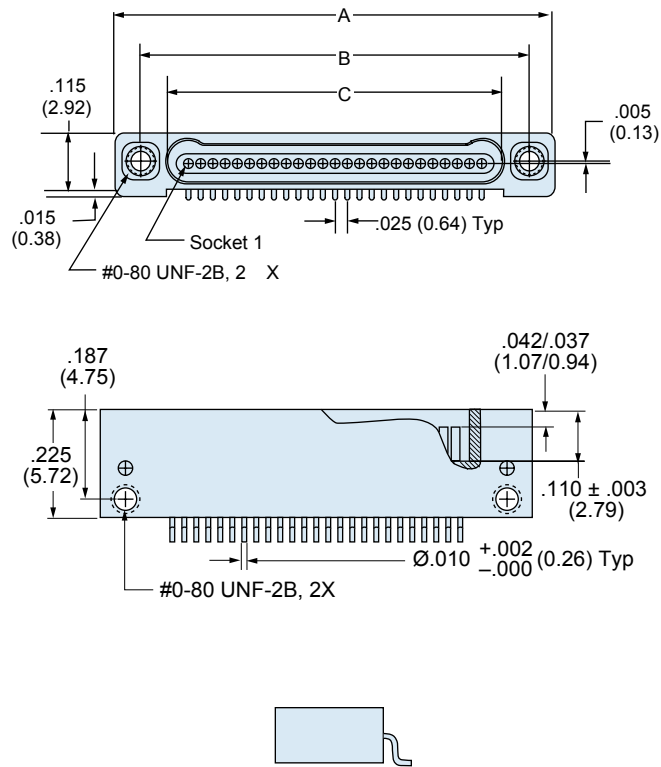

Layout	A		B BSC.		C BSC.	
	In. ± .005	mm. ± 0.13	In.	mm.	In.	mm.
5P	.400	10.16	.295	7.49	.184	4.67
5S	.400	10.16	.295	7.49	.185	4.70
9P	.500	12.70	.395	10.03	.284	7.21
9S	.500	12.70	.395	10.03	.285	7.24
15P	.650	16.51	.545	13.84	.434	11.02
15S	.650	16.51	.545	13.84	.435	11.05
21P	.800	20.32	.695	17.65	.584	14.83
21S	.800	20.32	.695	17.65	.585	14.86
25P	.900	22.86	.795	20.19	.684	17.37
25S	.900	22.86	.795	20.19	.685	17.40
31P	1.050	26.67	.945	24.00	.834	21.18
31S	1.050	26.67	.945	24.00	.835	21.21
37P	1.200	30.48	1.095	27.81	.984	24.99
37S	1.200	30.48	1.095	27.81	.985	24.02
51P	1.550	39.37	1.445	36.70	1.334	33.88
51S	1.550	39.37	1.445	36.70	1.335	33.91

Dimensions in inches (millimeters) and are subject to change without notice.

© 2013 Glenair, Inc.

Series 89 Nano Catalog

U.S. CAGE Code 06324/0CA77

Printed in U.S.A.


890-012 and 890-013 Right Angle Mount PCB, Single Row Nano Connector Surface Mount Type




Single Row
Connectors

Right Angle SMT Plug (Pin) Connector Layout 890-012


5 Contacts

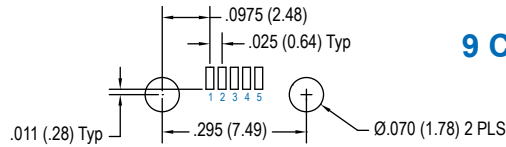


9 Contacts

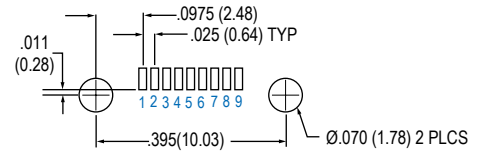


15 Contacts

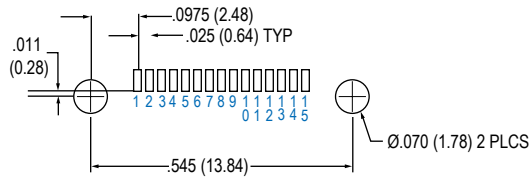


21 Contacts

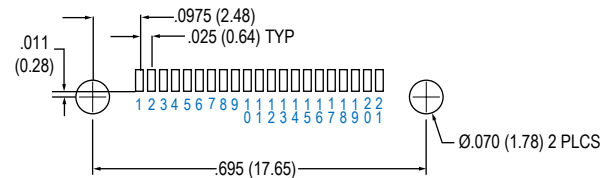


25 Contacts

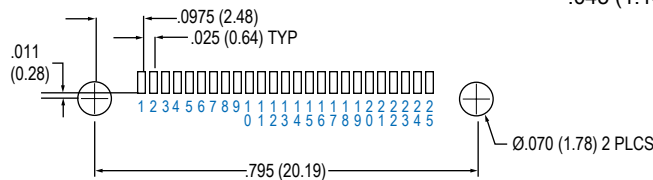




31 Contacts

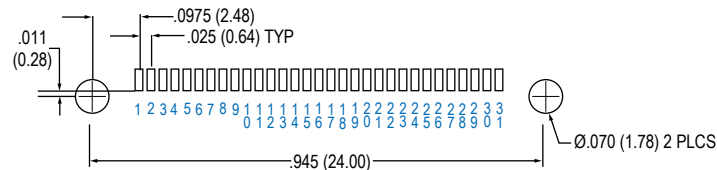

37 Contacts

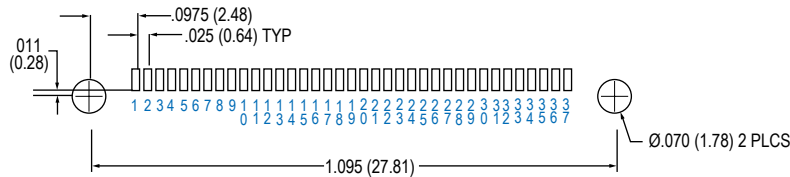

51 Contacts

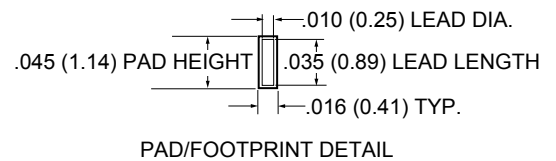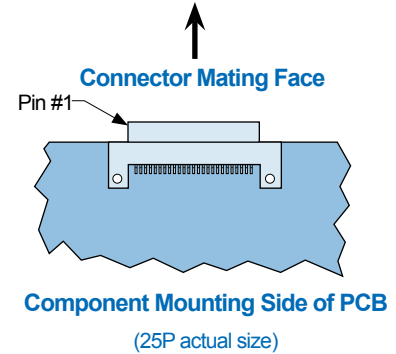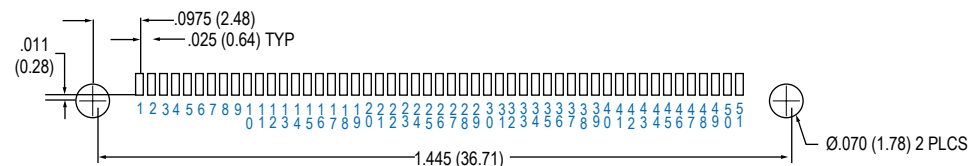


Layouts shown are for connector mounting side of PC Board.




890-012 and 890-013 Right Angle Mount PCB, Single Row Nano Connector Surface Mount Type

Right Angle SMT Receptacle (Socket) Connector Layout 890-013


5 Contacts

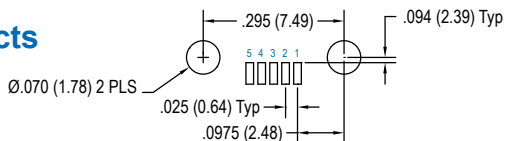


9 Contacts

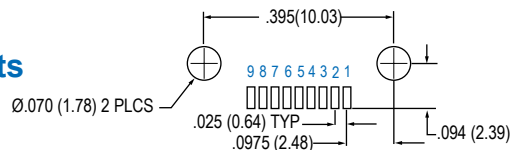


15 Contacts

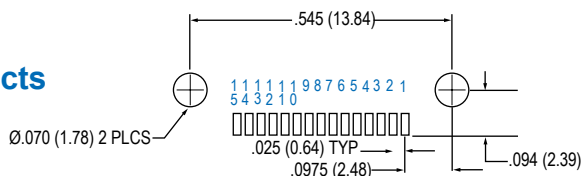


21 Contacts

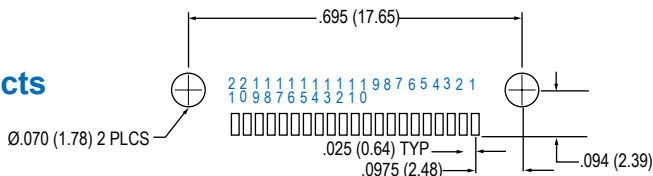


25 Contacts

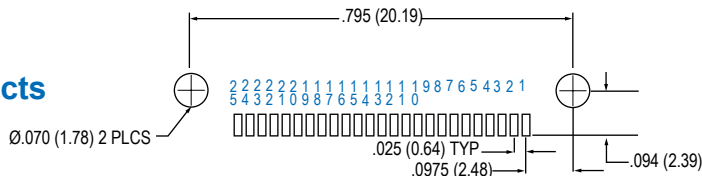


31 Contacts

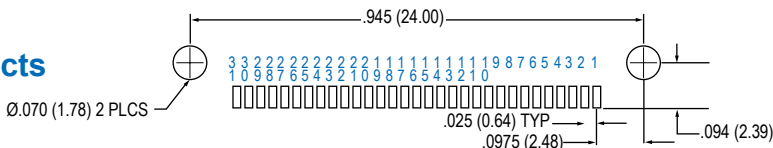

37 Contacts

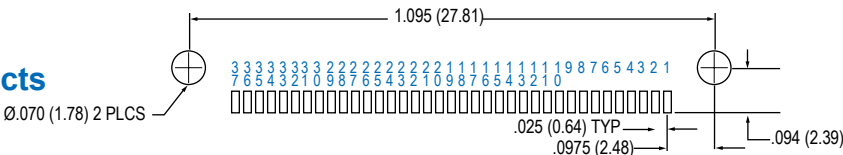

51 Contacts

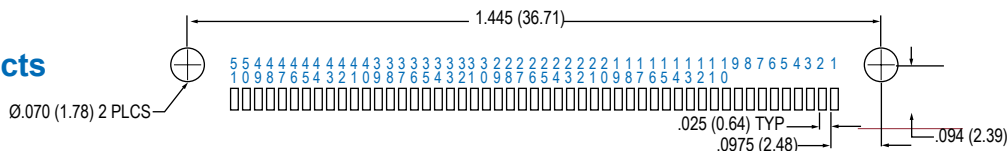


Connector Mating Face

Socket #1

Component Mounting Side of PCB

 (25S actual size)



PAD/FOOTPRINT DETAIL

Layouts shown are for connector mounting side of PC Board.