

IO-Link Touch Standard

84-ASKS-C14-04A5



<https://eao.com/p/84-ASKS-C14-04A5>

Your product:



84-ASKS-C14-04A5 IO-Link Touch Standard

FRONT

Front dimension:	Ø 30 mm
Front form:	round
Front bezel material:	Plastic

MOUNTING

Design:	flush
---------	-------

OPERATING-/INDICATION PART

Lens illumination:	illuminative
Lens shape:	flush
Lens material:	Plastic
Lens optics:	transparent
Symbol:	Standby (C14)

ELECTRICAL CHARACTERISTICS

Operating voltage:	8,4 - 32 V DC
--------------------	---------------

MECHANICAL CHARACTERISTIC

Terminal:	Connector M12
Weight:	0.015 kg
Switching system:	Capacitive
Operating force:	No actuating force necessary

AMBIENT CONDITION




IK front protection:	IK08
IP front protection:	IP69K
Operating temperature:	– 30 °C ... + 65 °C
Climate resistance:	Relative humidity, max. 95%, non-condensing

CERTIFICATE


Approbations:	CSA, EHEDG
Conformities:	CE, UKCA

OTHER




Short Description:	IO-Link Touch Standard, Ø 30 mm, flush, illuminative, Plastic, transparent, round, Plastic, Connector M12, IP69K, IK08, Standby (C14)
Housing colour:	Black
Housing material:	Plastic
Component layouts:	

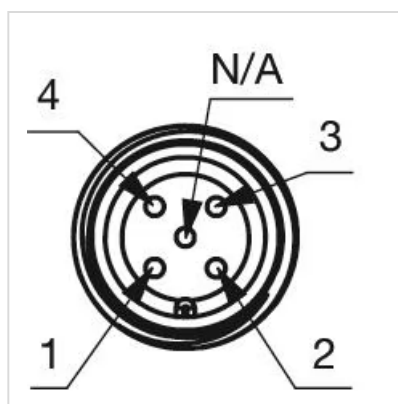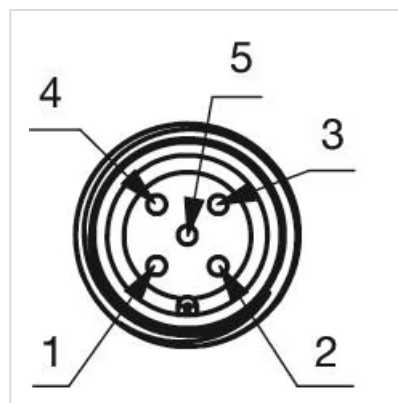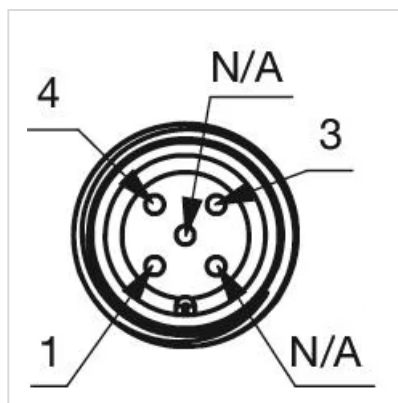

Mounting cut-outs:

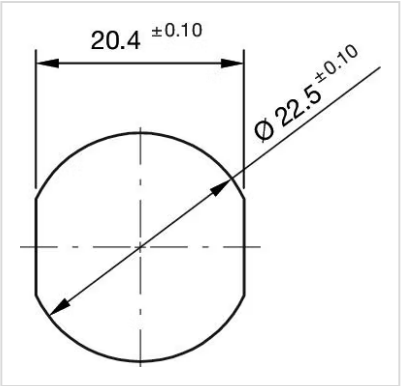

Wiring diagrams:

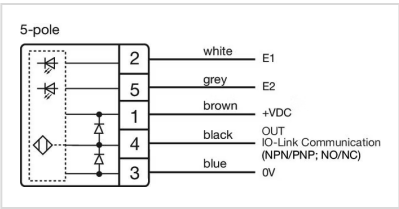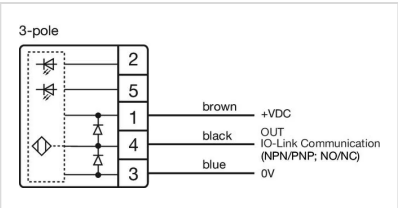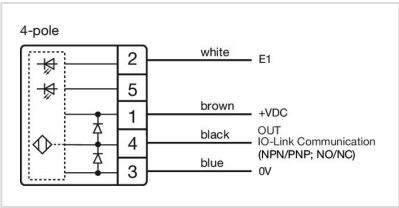

Dimension drawings:

