

IO-Link Touch Stainless Steel

84-ADKS-C16-04B4



<https://eao.com/p/84-ADKS-C16-04B4>

Your product:



84-ADKS-C16-04B4 IO-Link Touch Stainless Steel

FRONT

Front dimension:	Ø 30 mm
Front form:	round
Front bezel material:	Plastic

MOUNTING

Design:	flush
---------	-------

OPERATING-/INDICATION PART

Lens illumination:	illuminative
Lens shape:	flush
Lens material:	Plastic
Lens optics:	transparent

ELECTRICAL CHARACTERISTICS

Operating voltage:	8,4 - 32,00 V DC
--------------------	------------------

MECHANICAL CHARACTERISTIC

Terminal:	Connector M12
Weight:	0.015 kg
Switching system:	Capacitive
Operating force:	No actuating force necessary

AMBIENT CONDITION

IK front protection:	IK08
IP front protection:	IP69K
Operating temperature:	- 30 °C ... + 65 °C
Climate resistance:	Relative humidity, max. 95%, non-condensing

CERTIFICATE

Approbations:	CSA, EHEDG
Conformities:	CE, UKCA

OTHER


Short Description: IO-Link Touch Stainless Steel, Ø 30 mm, flush, illuminative, Plastic, transparent, round, Plastic, Connector M12, IP69K, IK08, START (B10)

Housing colour: Black


Housing material: Plastic

Symbol: START (B10)


Wiring diagrams:

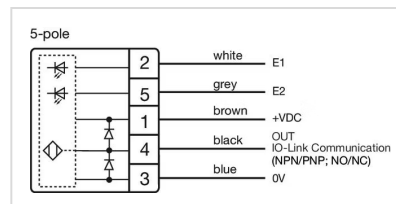

Component layouts:

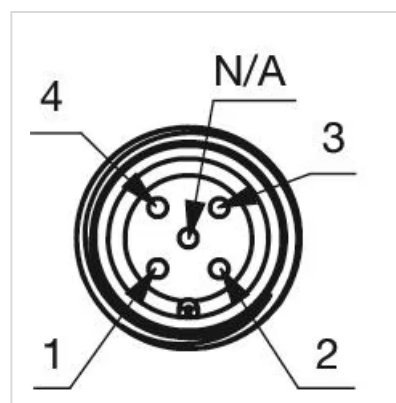

Dimension drawings:

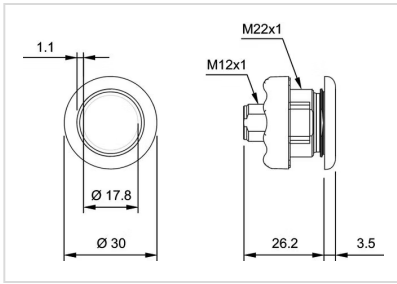

Mounting cut-outs:

