



PowerPAK 1212-8 Single to DIP-8 SMT Adapter (0.65 mm pitch, 3.3 x 3.3 mm body)

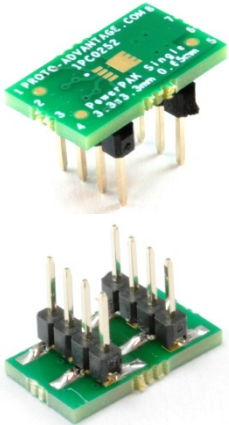


| REF. | DIMENSIONS | | | | | |
|------|------------|-------|------|--------|-------|------|
| | mm | | | inches | | |
| | MIN. | TYP. | MAX. | MIN. | TYP. | MAX. |
| A | | 1.88 | | | | |
| B | | 1.00 | | | | |
| C | | 0.40 | | | | |
| B2 | | 1.725 | | | | |
| C2 | | 2.235 | | | | |
| D | | 0.25 | | | | |
| D2 | | 0.635 | | | | |
| E | | 0.65 | | | | |
| F | | | | | 0.300 | |
| G | | | | | 0.100 | |
| H | | | | | 0.025 | |

Top View (SMT Footprint)

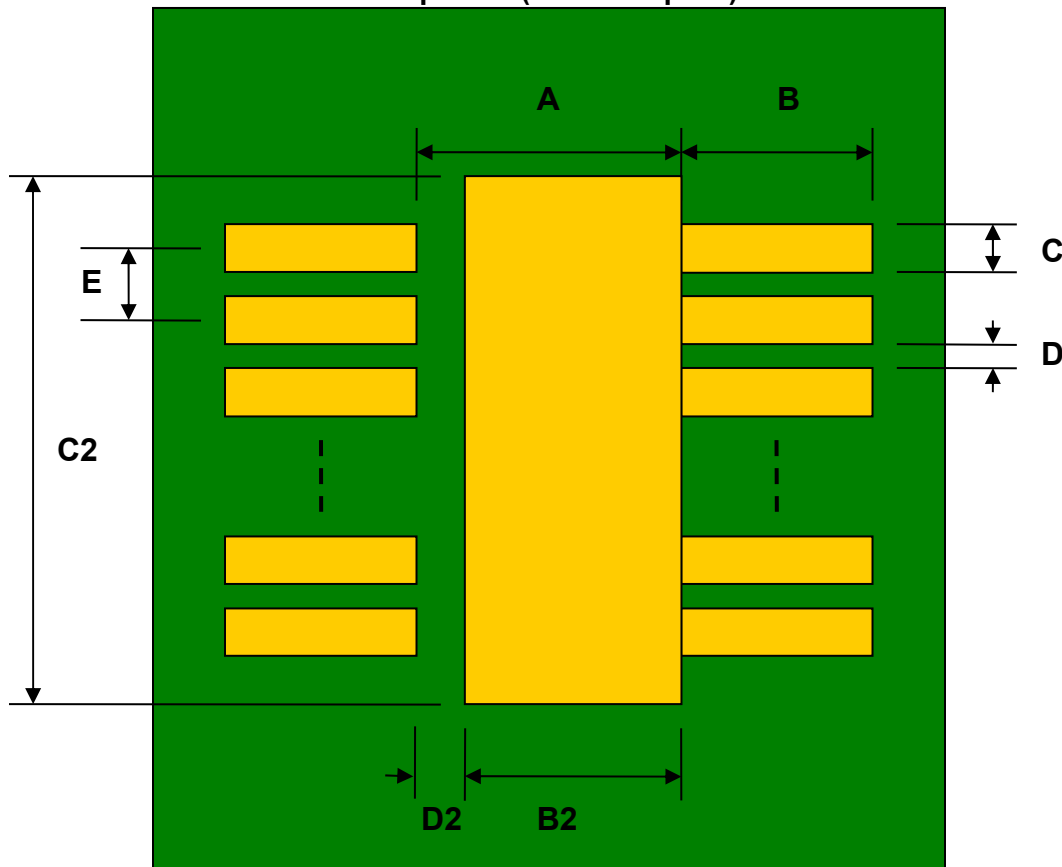


(Representative drawing only - not to scale)

Bottom View (DIP Pins)

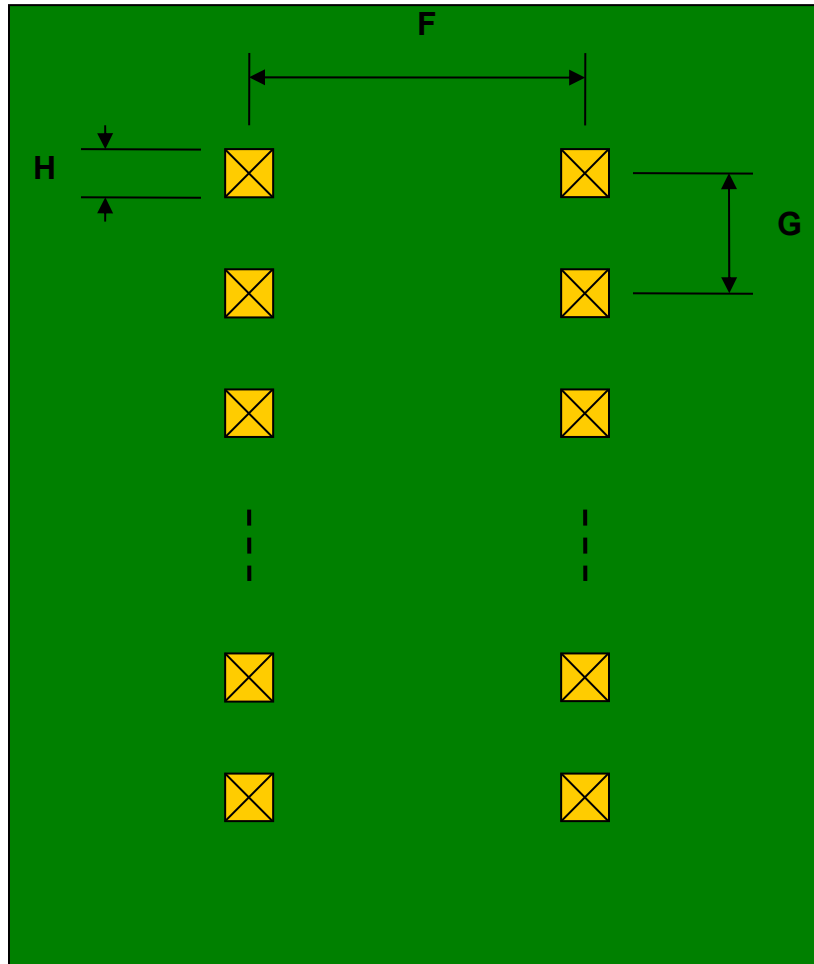

(Representative drawing only - not to scale)

Side View (DIP Pins)

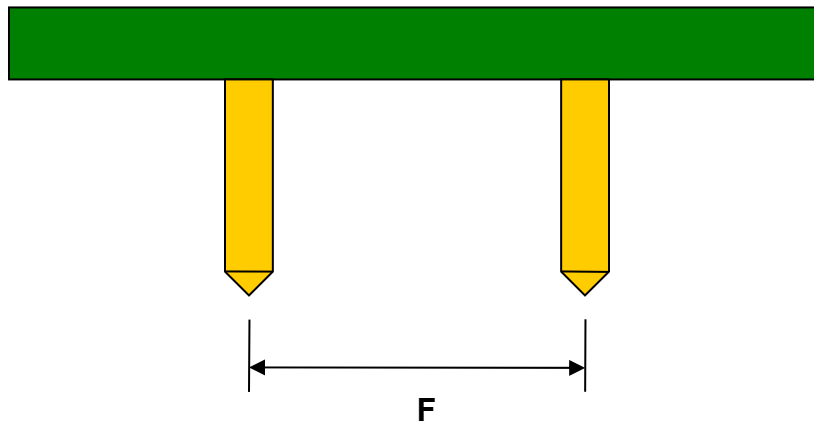

(Representative drawing only - not to scale)