

SUMMARY

Wires

High voltage 5



Image is for illustrative purpose only

Series	2P
Termination type	Female solder
IP rating	50
AWG wire size	0.00 - 0.00
Cable Ø	0.00 - 0.00 mm
Status	active
Matching parts	CAB.H05.GLA.C72A

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model	CK*: Fixed receptacle with two nuts (back panel mounting)
Keying	
Housing Material	PSU (Polysulfone), gray
Weight	4.68 g

Performance

Configuration	2P.H05 : 5 High Voltage
Insulator	
Rated Current	8 Amps

Specifications


Test voltage contact-contact : 11.6 kV rms
Air clearance min.: 7.96 mm
Creepage distance min.: 7.96 mm

Others

Temp (min / max): -50°C / +150°C

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

DRAWINGS

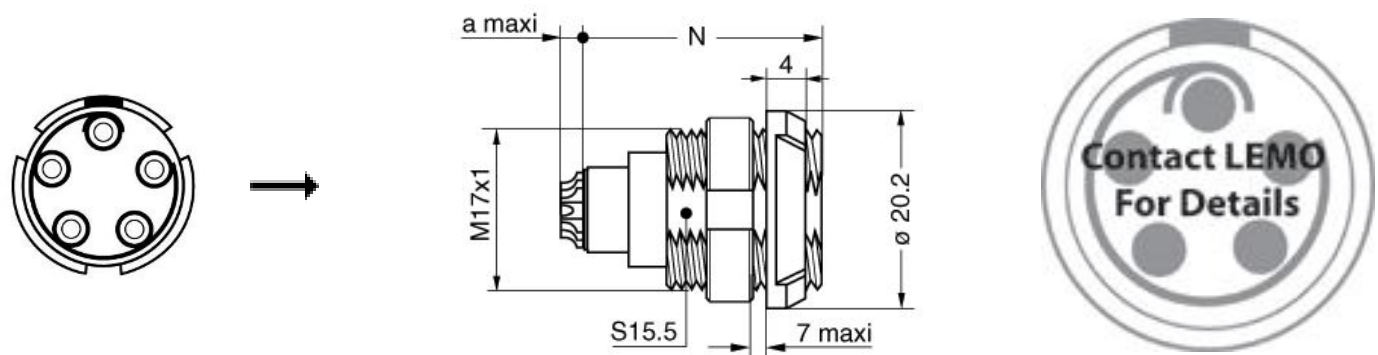

Dimensions

	N	a
mm.	23.8	3.4-4.9
in.	0,94	0,13

RECOMMENDED BY LEMO

Tools

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.