



RAD-PAK-70 to DIP-70 SMT Adapter (0.635 mm pitch, 20.8 x 25.4 mm body)

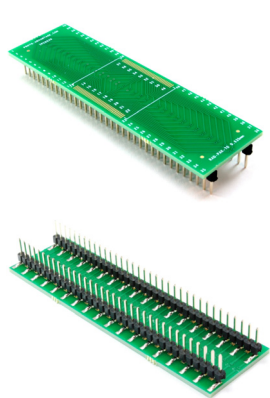


REF.	DIMENSIONS					
	mm			inches		
	MIN.	TYP.	MAX.	MIN.	TYP.	MAX.
A		19.00				
B		2.00				
C		0.335				
D		0.30				
E		0.635				
F					0.600	
G					0.100	
H					0.025	

Top View (SMT Footprint)

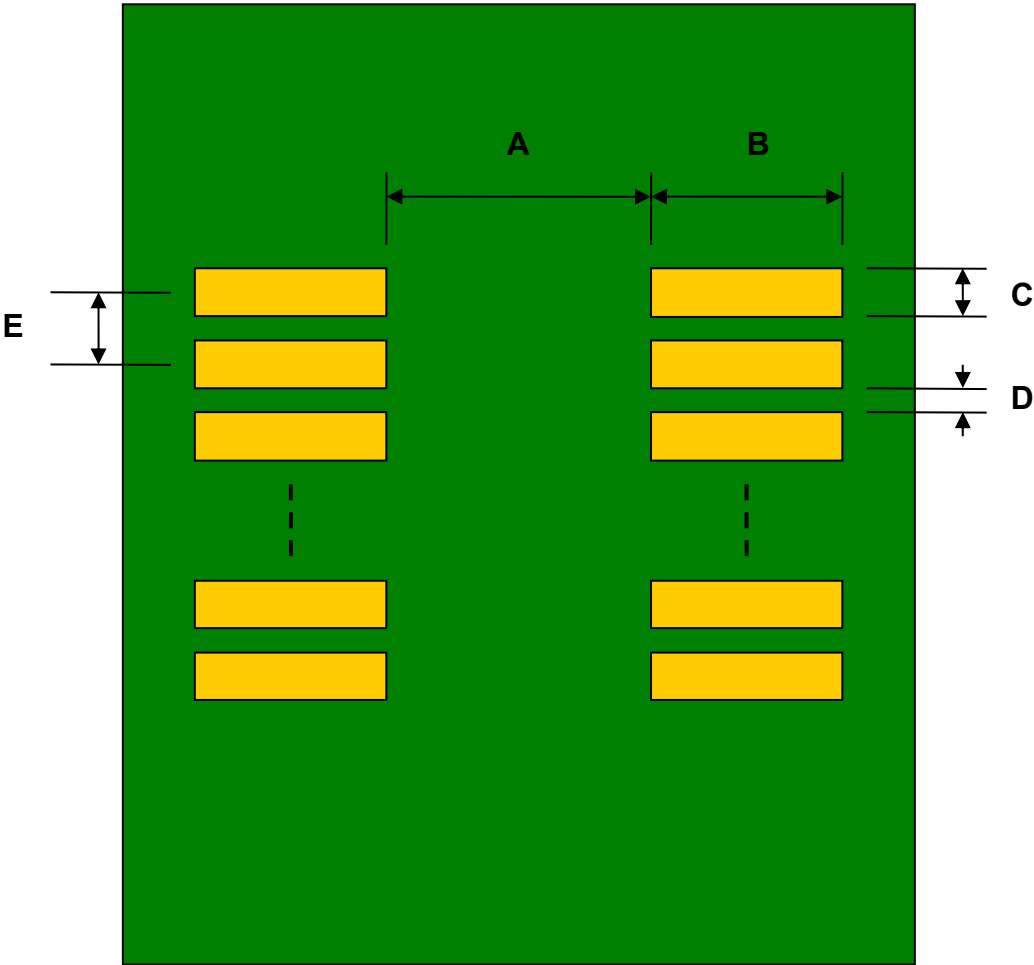


(Representative drawing only - not to scale)

Bottom View (DIP Pins)

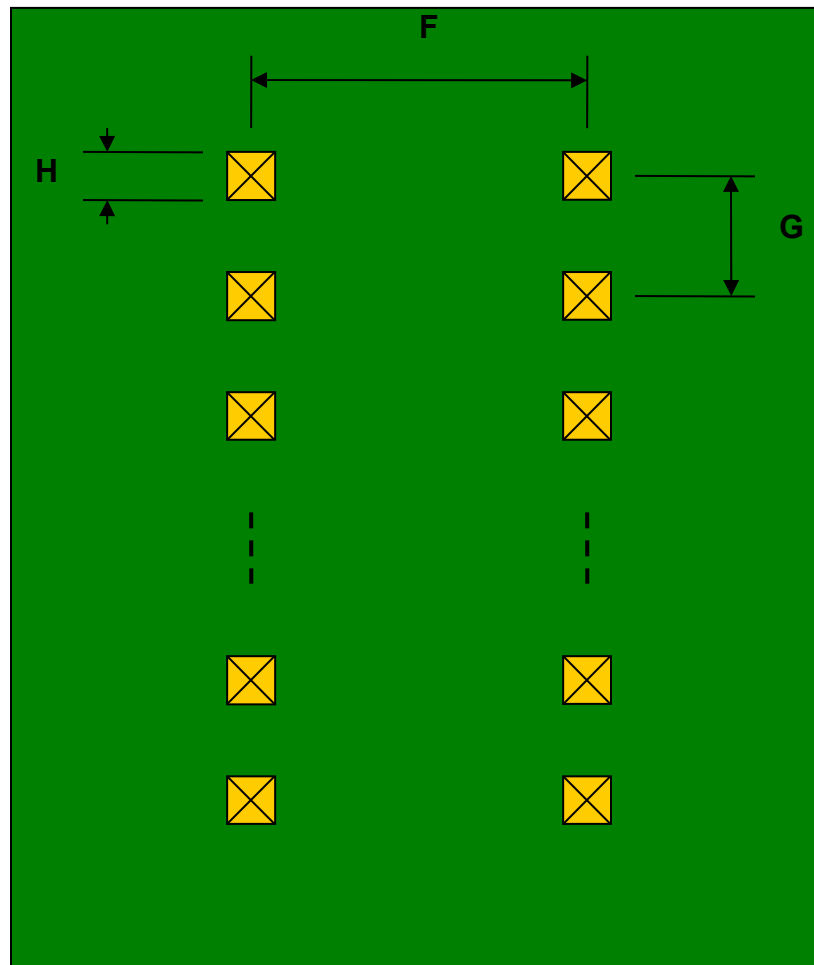

(Representative drawing only - not to scale)

Side View (DIP Pins)

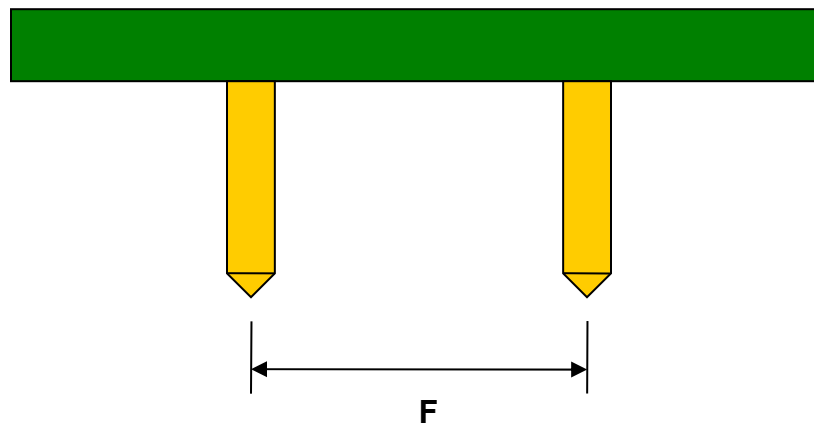

(Representative drawing only - not to scale)