

SUMMARY

Wires



Image is for illustrative purpose only

Series	2P
Termination type	Male crimp mixed / multi coax
IP rating	50
AWG wire size	0.00 - 0.00
Cable Ø	7.30 - 9.20 mm
Status	active

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model CA*: Straight plug with cable collet

Keying

Housing Material PSU (Polysulfone), gray

Weight 7.96 g

Performance

Configuration

Insulator L: PEEK for solder contacts


Rated Current

Others

Endurance (Shell): >1000 mating cycles

Temp (min / max): -50°C / +150°C

DRAWINGS

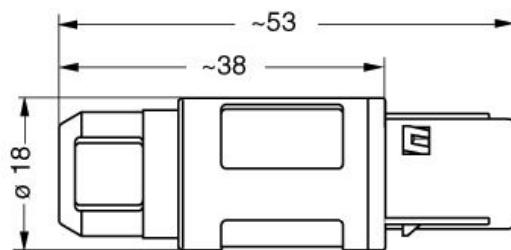

RECOMMENDED BY LEMO

Tools

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.