

## SUMMARY

### # Wires

Coax	1
------	---



*Image is for illustrative purpose only*

Series	0A
Termination type	Male solder
IP rating	50
AWG wire size	0.00 - 0.00
Cable Ø	4.00 - 5.10 mm
Status	active

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model	FFA*: Straight plug with cable collet
Keying	
Housing Material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Weight	8.05 g

### Performance

Configuration	0A.250 : 1 Coax (50 Ohm)
Insulator	
Rated Current	

### Specifications


Contact Type: Coaxial 50 Ohm (Solder)

### Others

Endurance (Shell): 5000 mating cycles  
Salt Spray Corrosion: >1000 hr

*LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.*

# DRAWINGS

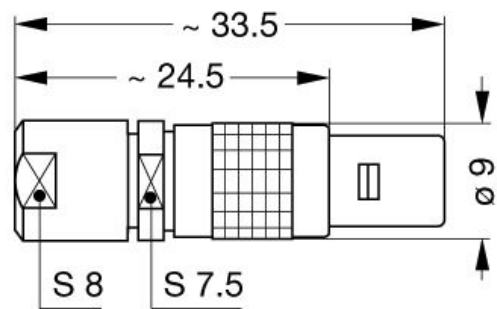


## Dimensions

	A	L	M	S1	S2
mm.	9	33.5	24.5	7.5	8
in.	0,35	1,32	0,96	0,30	0,31

# RECOMMENDED BY LEMO

## Tools

## Cables

158480	PUR	Black	
158490	PVC	Black	
CCX.50.088.292495N	PVC	Black	
CCX.50.RG5.8CU50N	PVC	Black	

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.