

SUMMARY

Wires

Low	16
High	0
Coax	0
Triax	0
Quad	0
Fiber	0
Fluidic	0

Series	C
Termination type	Female solder
IP rating	66
Cable Ø	7.30 - 9.20 mm
Matching parts	CFB.M16.GLA.C92GZ
Status	active
Alternative part	



Image is for illustrative purpose only

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model	CS*: Free receptacle with cable collet, watertight (IP 66) and nut for fitting a bend relief
Keying	3 keys (alpha=0, gamma=60; Plug: male contacts; Receptacle: female contacts)
Housing Material	PSU (Polysulfone), gray
Cable Fixing	∅ 7.3 - 9.2 mm
Variant	
Weight	11.68 g

Performance

Configuration	2P.M16 : 16 Low V.
Insulator	
Rated Current	6 Amps

Specifications

Test voltage (kV rms) Contact-contact:	1.5
Air clearance min. (mm) or Creepage distance min. (mm):	0.65


LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Others

F ret (min): 150 N
F ret (max): 250 N
Steam sterilization: 20 times
IP Rating: 66

DRAWINGS

Draws

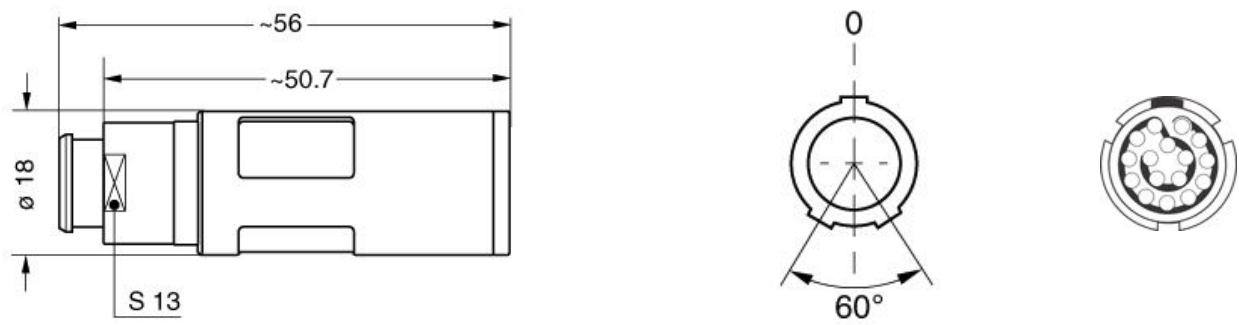

Dimensions

	A	L
mm.	18	56
in.	0,71	2,20

RECOMMENDED BY LEMO

Tools

None

Cables

CMN.16.B22.084PG3Z		Grey	
--------------------	--	------	--

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.