

Actuator

704.097.018



<https://eao.com/p/704.097.018>

Your product:



704.097.018 Actuator

FRONT

Front bezel material:	Aluminium
Front bezel colour:	Nature
Front dimension:	Ø 35 mm

MOUNTING

Design:	flush
---------	-------

OPERATING-/INDICATION PART

Lever colour:	Black
Lever material:	plastic
Lever shape:	long

ELECTRICAL CHARACTERISTICS

Standards:	The switches comply with the "Standards for low-voltage switching devices" DIN EN 60947-1
------------	---

MECHANICAL CHARACTERISTIC

Mechanical lifetime:	≤2.5 Mio. cycles of operation
Weight:	0.056 kg
Switching positions:	3 positions
Switching angle:	42° left / 42° right
Switching action:	Maintained - Rest - Momentary

AMBIENT CONDITION

Storage temperature: - 40 °C ... + 85 °C

Operating temperature: - 40 °C ... + 55 °C

IP Protection: IP65 front side

OTHER

max. number of switching elements: 3


Short Description: Actuator, Ø 35 mm, non illuminative, Black, long, Nature, Aluminium, anodised, Maintained - Rest - Momentary

Hints: Max. 3 switching elements can be clipped on


Wiring diagrams:



Mounting cut-outs:

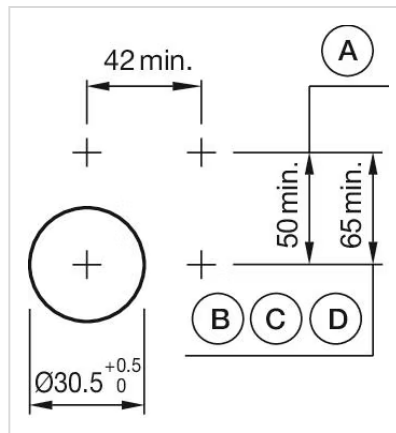

Dimension drawings:

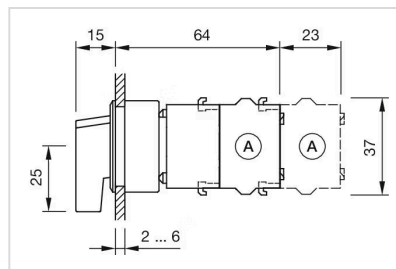

Switching positions:

