
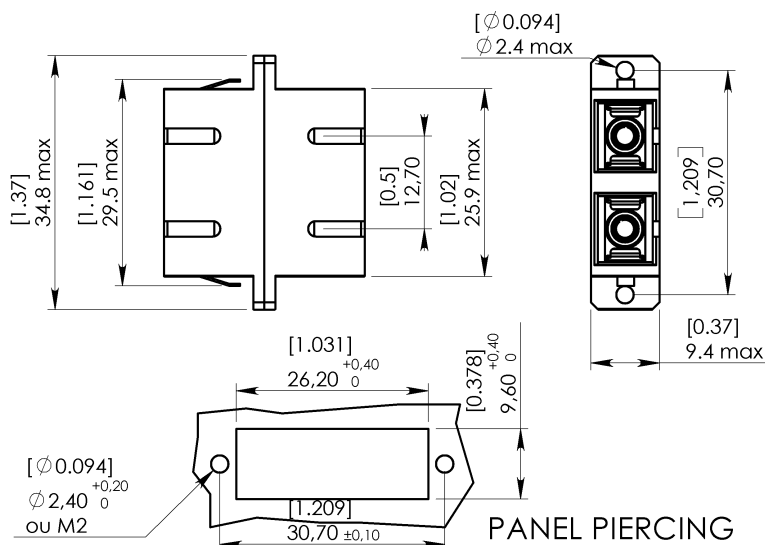


Original dimensions in mm [inch]

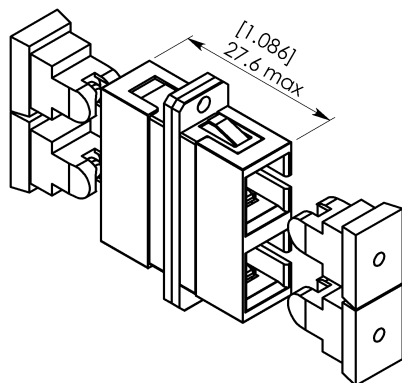

GENERAL

Type :	IEC 60874-19 SC type. Push pull latching system Body color : AQUA
Mounting :	Snap-in (or screw-in) mounting max. panel thickness 1.6 mm
Alignment sleeve :	Zirconia

CHARACTERISTICS *(Dependant on fiber or cable construction)*

Material : Plastic moulded

Material in accordance with BELLCORE
GR 326 CORE Issue 2, par.3.3.1
Inflammability V1 (UL94)
Stainless steel

Clip

Optical : Attenuation (according to IEC 61300-3-4:Substitution method, 7 type) at 1310nm :
0.02 dB Max / 0.01 dB Typ

Mechanical : Durability
Plug Retention

Belcore 326, 500 cycles
> 68 N

Environmental : Temperature range (storage/operating) -40°C to +85°C

Salt spray : EIA/TIA -455-16A, 35°C, 168 hr.

Vibration test : Bellcore 326,10 to 50 Hz,2 hrs./axis

Proof test : Bellcore 326, Straight pull : 6.8 Kg load at 0°
Side pull : 3.5 Kg load at 90°

CREATION					RADIAL [®] 101, rue P. Hoffmann 93116 ROSNY/BOIS FRANCE Tel : (33) 0149353535 Fax : (33) 0148546363
PEN/EP EPM 1005 Name: S.P Date: dec, 30 2010 Appr.: H.D					
	Issue	Revisions	Name	Appr.	