


## Center Plate Insert, Decora Style - Vertical, 3 Ports, TAA

MODEL NUMBER: N042D-003V-WH

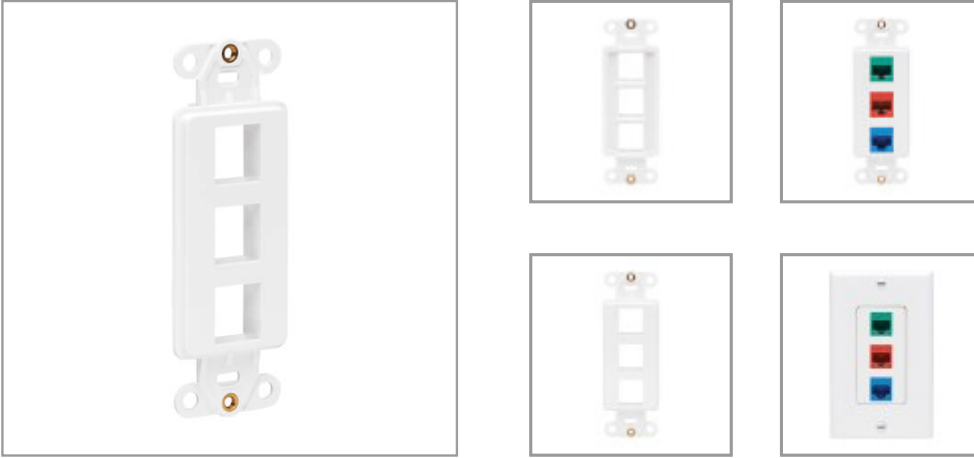

Clean, simple insert mounts within Decora-style wall plate for terminating in-wall audio/video, voice or Ethernet cable installations.

### Features

**Decora-Style Face Plate Connects Audio/Video, Voice and Data Cable Lines at the Wall** This vertical-style center insert provides a clean, simple method for your premise wiring applications, including home theater (audio/video), VoIP phones (voice) and Ethernet (data). Any type of keystone jack, including those used in HDMI, DisplayPort, RCA, USB and Cat5e/6/6a installations, snaps easily into the cutouts for quick cable connection.

**High-Impact Construction Designed to Blend In Seamlessly** The Decora-style polycarbonate insert plate is white and blends elegantly into any home or office décor for a sleek, professional installation. Mounting screws are included for flush mounting the insert with a compatible Decora-style wall plate (sold separately).

## Specifications

OVERVIEW	
UPC Code	037332249715
Technology	Cat5/5e; Cat6; Cat6a; DisplayPort; HDBaseT; HDMI; USB 2.0 (High Speed)
Country/Region	Global
CONNECTIONS	
Number of Ports	3
Side A - Connector 1	KEYSTONE JACK CUTOUT
Side B - Connector 1	KEYSTONE JACK CUTOUT
PHYSICAL	

### Highlights

- Ideal for home theater, VoIP or Ethernet premise wiring installations
- Compatible with any type of keystone jack, including HDMI, Cat5/6, USB and DisplayPort
- High-impact polycarbonate construction designed to last long in your décor
- Hardware included for mounting flush with compatible Decora-style wall plate

### Applications

- Complete your premise wiring application with a clean, sleek-looking Decora-style appearance

### Package Includes

- N042D-003V-WH Center Plate Insert, Decora Style - Vertical, 3 Ports
- (2) Mounting screws



Powering Business Worldwide

TRIPP LITE  
SERIES

Color	White
Material of Construction	ABS
Total Number of Ports	3
<b>ENVIRONMENTAL</b>	
Operating Temperature Range	14° to 140°F (-10° to 60°C)
Storage Temperature Range	-40° to 154°F (-40° to 68°C)
Relative Humidity	10% to 90% (Non-Condensing)
<b>FEATURES &amp; SPECIFICATIONS</b>	
Antibacterial	No
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Compliance	RoHS; REACH; Trade Agreements Act (TAA)
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.