

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300680079](#)
Status: **Active**
Overview: [BradPower Cordsets and Receptacles](#)
Description: BradPower D-Size (1 3/8"-M35) 4-Pole Trunk Tee, with 4-Pole BradPower D-Size (1 3/8"-M35) Drop, Gray

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E258922

General

Product Family Industrial Tees and Splitters
Series [130068](#)
IP Rating IP67
Overview [BradPower Cordsets and Receptacles](#)
Product Name BradPower D-Size
Type Power Tap Tee
UPC 78172553712

Physical

Drop Connector BradPower D-Size (1 3/8"-M35)
Drop Gender Female
Keyway Single
Left Trunk Connector BradPower D-Size (1 3/8"-M35)
Left Trunk Gender Female
Leg 1 Length N/A
Leg 2 Length N/A
Material - Cable Jacket N/A
Material - Connector Body PVC
Material - Coupling Nut Anodized Aluminum
Net Weight 303.907/g
Poles 4
Right Trunk Connector BradPower D-Size (1 3/8"-M35)
Right Trunk Gender Male
Temperature Range - Operating -20°C to +90°C

Electrical


Current - Maximum per Contact 25.0A
Voltage - Maximum 600V AC/DC

Material Info

Engineering Number TC40C40-200

Reference - Drawing Numbers

Sales Drawing SD-130068-010-001

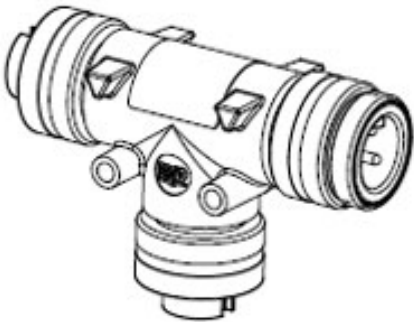

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

**Compliant with
Exemption 6(c)**

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[130068](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION