


Micro SMD-14 to DIP-14 SMT Adapter (0.5 mm pitch, 2.10 x 2.40 mm body)


REF.	DIMENSIONS					
	mm			inches		
	MIN.	TYP.	MAX.	MIN.	TYP.	MAX.
C		0.275				
D		0.158				
E		0.50				
E2		0.433				
F					0.300	
G					0.100	
H					0.025	

Top View (SMT Footprint)

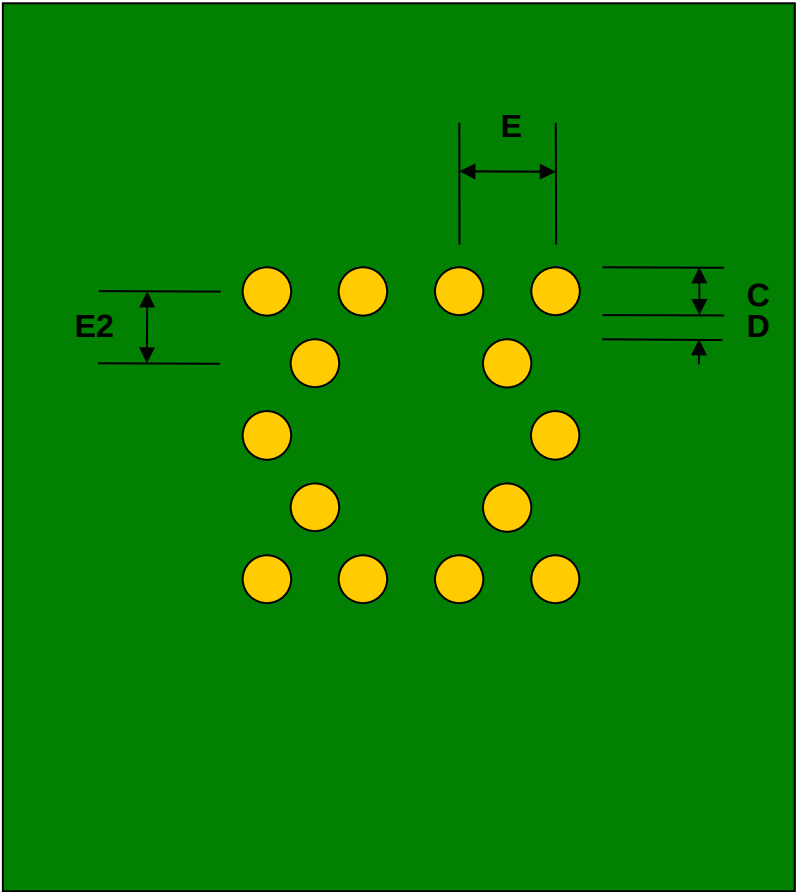


(Representative drawing only - not to scale)

Bottom View (DIP Pins)

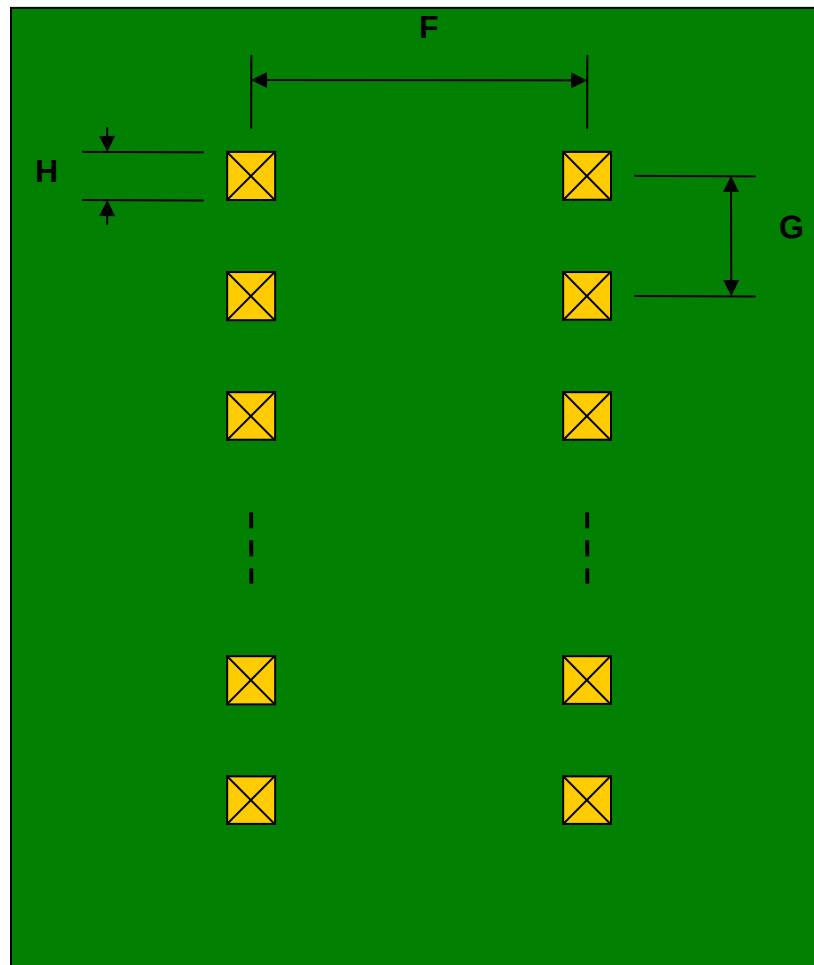

(Representative drawing only - not to scale)

Side View (DIP Pins)

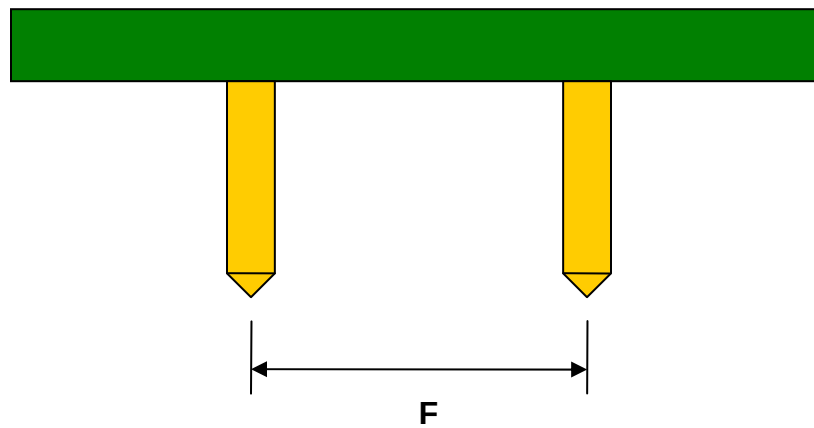

(Representative drawing only - not to scale)