

Actuator

45-
2630.29E0.000



<https://eao.com/p/45-2630.29E0.000>

Your product:



45-2630.29E0.000 Actuator

FRONT

| | |
|-----------------------|---------|
| Front dimension: | Ø 40 mm |
| Front bezel colour: | Silver |
| Front bezel material: | Metal |

MOUNTING

| | |
|---------|--------|
| Design: | raised |
|---------|--------|

OPERATING-/INDICATION PART

| | |
|--------------------|---------------|
| Lens illumination: | illuminative |
| Lens colour: | Red |
| Lens shape: | mushroom-head |
| Lens material: | Plastic |
| Lens optics: | transparent |


MECHANICAL CHARACTERISTIC

| | |
|----------------------|-----------------------------|
| Weight: | 0.063 kg |
| Switching action: | Maintained |
| Switching system: | Slow-make switching element |
| Release type: | Pull unlock |
| Mechanical lifetime: | 500 000 cycles of operation |
| Operating frequency: | Max. 1 800/h |


AMBIENT CONDITION

| | |
|-------------------------------|--|
| IP front protection: | IP66, IP67, IP69K |
| Operating temperature: | – 25 °C ... + 70 °C |
| Storage temperature: | – 40 °C ... + 80 °C |
| Climate resistance: | During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6 |
| Vibration resistance: | According to IEC 60068-2-6: 20 ... 500 Hz: 5 g |
| Shock resistance: | According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms |

OTHER
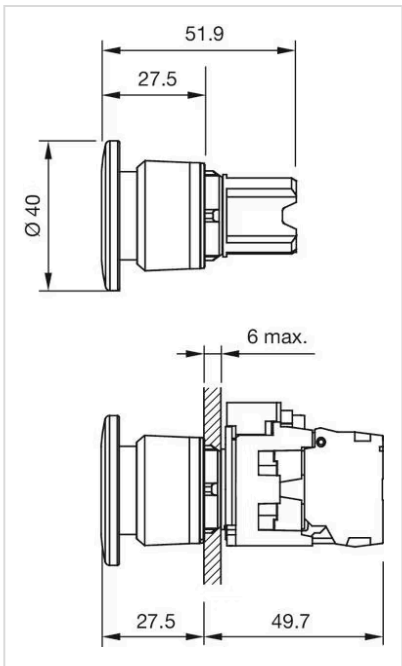
| | |
|----------------------------|--|
| Housing colour: | Silver |
| Housing material: | Metal |
| Short Description: | Actuator, Ø 40 mm, mushroom-head, illuminative, Red, Plastic, transparent, Silver, Metal, Maintained, IP66, IP67, IP69K, Pull unlock |
| Dimension drawings: |  |

Wiring diagrams:

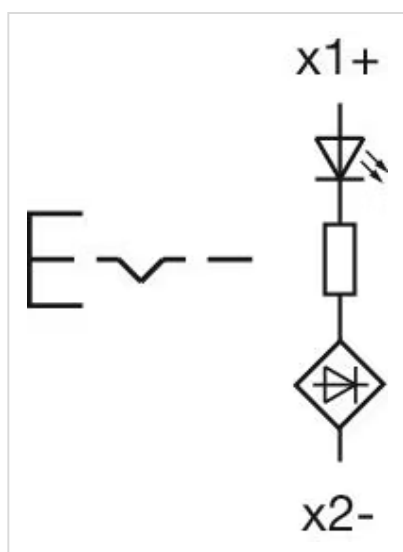

Mounting cut-outs:

