

SUMMARY

Wires

High voltage 5



Image is for illustrative purpose only

Series 2P
Termination type Male solder
IP rating 50
AWG wire size 0.00 - 0.00
Cable Ø 5.30 - 7.20 mm
Status active

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model CA*: Straight plug with cable collet and nut for fitting a bend relief

Keying

Housing Material PSU (Polysulfone), gray

Performance

Configuration 2P.H05 : 5 High Voltage

Insulator

Rated Current 8 Amps

Specifications

Test voltage contact-contact : 11.6 kV rms


Air clearance min.: 7.96 mm

Creepage distance min.: 7.96 mm

Others

Temp (min / max): -50°C / +150°C

DRAWINGS

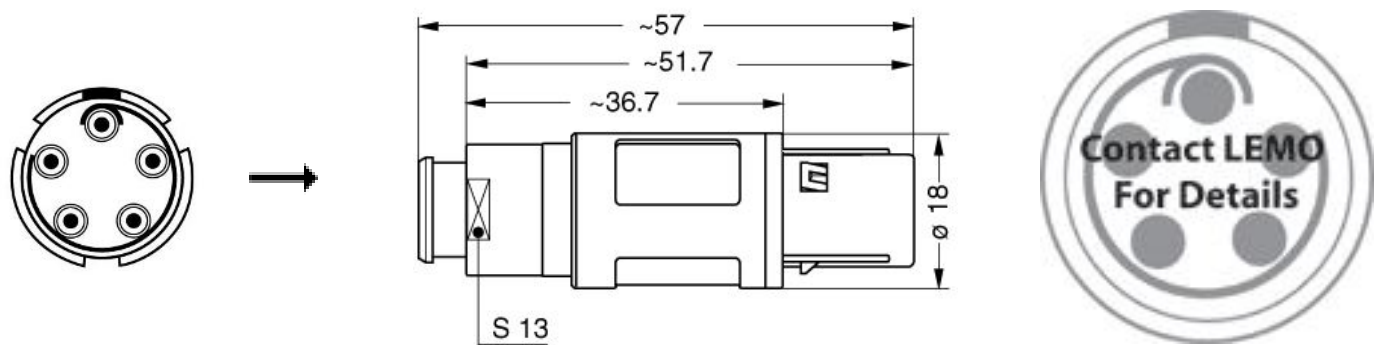

RECOMMENDED BY LEMO

Tools

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.