

SUMMARY

Wires

High voltage 8



Image is for illustrative purpose only

Series	2P
Termination type	Female solder
IP rating	50
AWG wire size	0.00 - 0.00
Cable Ø	3.20 - 5.20 mm
Status	active

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model CA*: Straight plug with cable collet

Keying

Housing Material PSU (Polysulfone), black

Weight 9.79 g

Performance

Configuration 2P.H08 : 8 High Voltage

Insulator

Rated Current 6.5 Amps

Specifications

Test voltage contact-contact : 10.3 kV rms

Air clearance min.: 7.42 mm


Creepage distance min.: 7.42 mm

Others

Temp (min / max): -50°C / +150°C

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

DRAWINGS

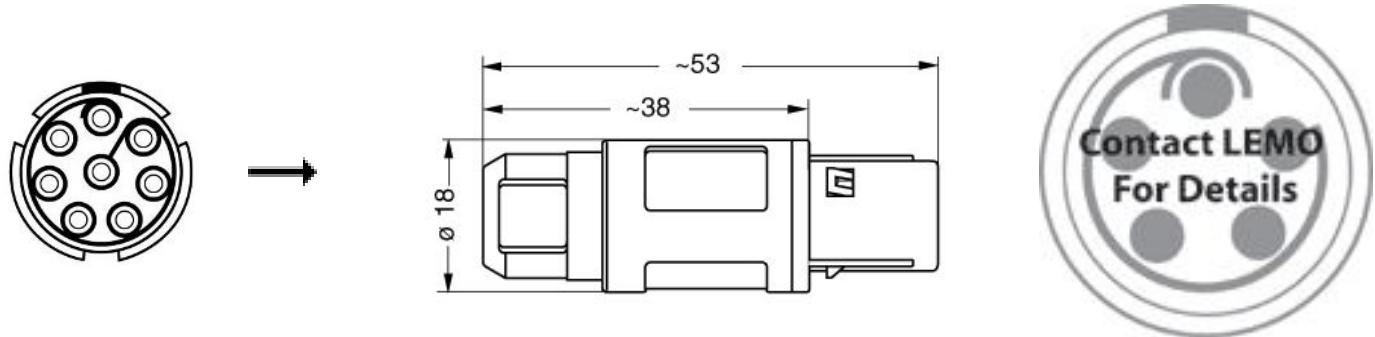

RECOMMENDED BY LEMO

Tools

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.