
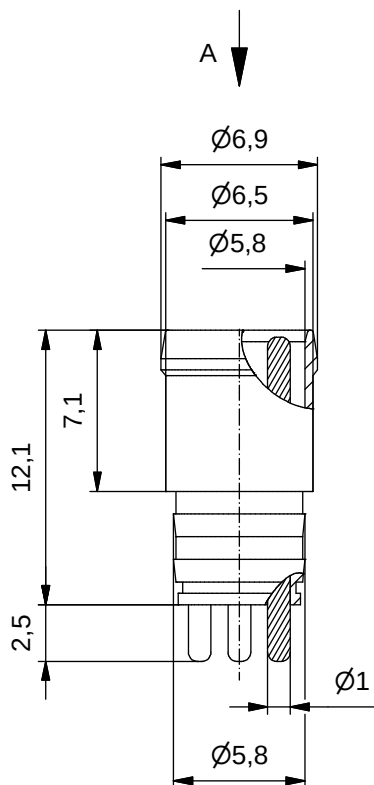
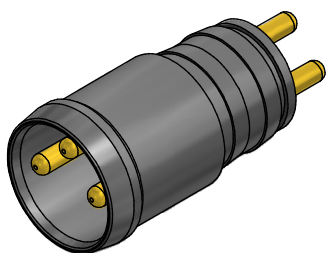


Technical specification:

Rated voltage: IEC 61076-2-104	3pos 4pos 60 V 30 V
Current rating: IEC 61076-2-104	3 A bei 40°C
Insulation resistance: IEC 60512	$\geq 100 \text{ M}\Omega$
Pollution degree: IEC 60664-1	3/2
Degree of protection: IEC 60529	IP 67, in mated condition
Temperature range: IEC 60664-1	-30°C ... +85°C
Mating cycles: IEC 60512-9a	≥ 100

Materials:

Contact:	CuZn
Contact plating:	Nickel, gold plated
Contact carrier:	PA GF, UL 94

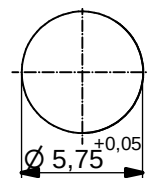

Part no:	Description:	Pos
42-01012	SAL - 8 - ESP3 - P	3
42-01014	SAL - 8 - ESP4 - P	4

DO NOT ALTER CAD DRAWING BY HAND Directive 2002/95/EC RoHS compliant	Index: d 02.03.11 fro Ä3914 Data sheet revised	dim. in mm	title: Male socket M8x1 with dip solder	
	THIS DRAWING MAY NOT BE COPIED OR REPRODUCED IN ANY WAY, AND MAY NOT BE PASSED ON TO A THIRD PARTY WITHOUT WRITTEN PERMISSION. OWNERSHIP AND COPYRIGHT OF CONEC GmbH	date	dwg no: 42K1A113	
		name		

	date	name
drawn	15.10.08	Fromm
appd.	15.10.08	Mankopf

CONEC®

part no: