
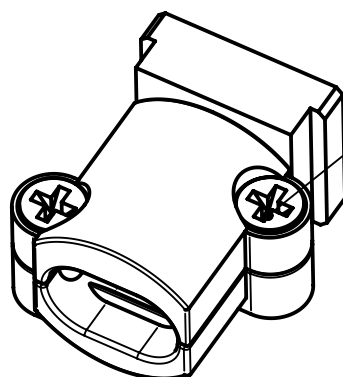
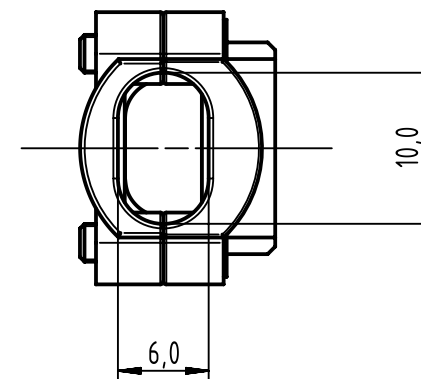
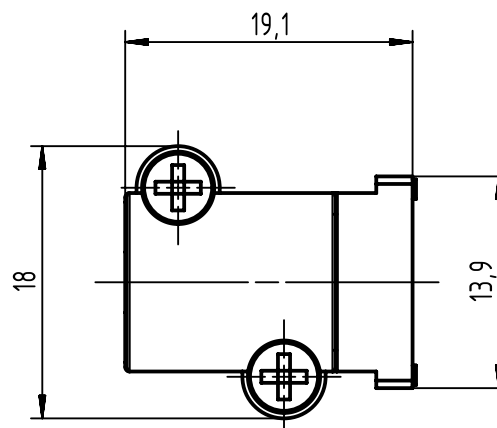


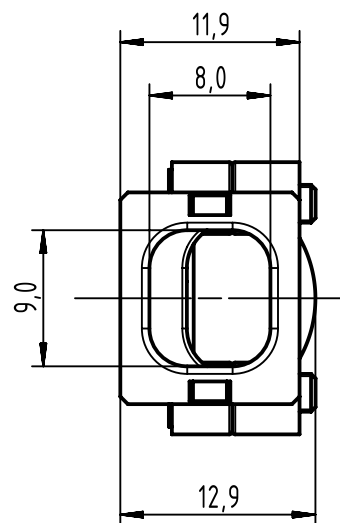

Clamp screws(x2)  
TYPE Z pozidriv  
Screwdriver head #1  
Max. torque=0,4Nm

Schraube (2x)  
Typ Z pozidriv  
Schraubendreher #1  
max. Drehmoment 0,4Nm

For cable diameter between 7 and 10mm  
Für Kabeldurchmesser von 7 - 10mm

InduCom Kabelklemme für 9- 37-pol. Gehäuse

|                                                                                     |  |                       |  |                                                     |  |                       |  |                             |  |                    |  |                                                          |  |             |  |
|-------------------------------------------------------------------------------------|--|-----------------------|--|-----------------------------------------------------|--|-----------------------|--|-----------------------------|--|--------------------|--|----------------------------------------------------------|--|-------------|--|
|  |  | All rights reserved   |  | Created by<br>ZENG D                                |  | Inspected by<br>LUOK  |  | Standardisation<br>HOFFMANN |  | Date<br>2018-03-26 |  | State<br>Final Release                                   |  |             |  |
| HARTING Electronics GmbH                                                            |  | Department EC PD - CN |  | Title<br>InduCom cable clamp for 9 to 37-pole hoods |  |                       |  |                             |  |                    |  | Doc-Key / ECM-Nr.<br>100233372/UGD/002/D<br>500000133025 |  |             |  |
| D-32339 Espelkamp                                                                   |  |                       |  | Type<br>TB                                          |  | Number<br>61030000044 |  |                             |  |                    |  | Rev.<br>D                                                |  | Page<br>1/1 |  |