

SCA610-E23H1A

To be discontinued

AEC-Q100


REACH

Note: This datasheet may be out of date.

Please download the latest datasheet of SCA610-E23H1A from the official website of Murata Manufacturing Co., Ltd.

<http://www.murata.com/en/products/productdetail?partno=SCA610-E23H1A>

Appearance & Shape

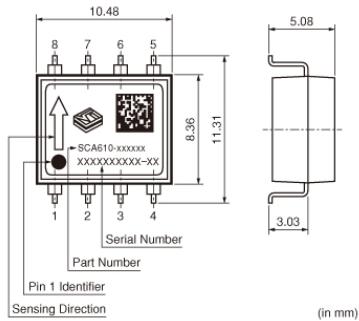

Packaging Information

Packaging	Specifications	Standard Packing Quantity
-1	330mm Embossed Tape	100

Attention

1. This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, its specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.

2. This datasheet has only typical specifications because there is no space for detailed specifications.

Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.

SCA610-E23H1A

Specifications

Output Type	Analog
Axis	1(X)
Maximum Range	±1.5g
Supply Voltage	5V
Offset Temp. Characteristic	±125mg
Sensitivity	1.33V/G
Amplitude Response	50Hz
Mass	0.73g

2 of 2

Attention

- 1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, its specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.
- 2.This datasheet has only typical specifications because there is no space for detailed specifications.
Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.