

MISCELLANEOUS

ADAPTORS

• BNC / 4 mm dia.BANANA ADAPTORS

These adaptors are designed to uncouple electric signals from input and output terminals of a measuring device fitted with male or female BNC fixed connectors.

CHARACTERISTICS

- Dielectric withstanding voltage

– Insulation resistance

: 2 500 V rms – 50 Hz

: 10⁵ MΩ

Electrical termination

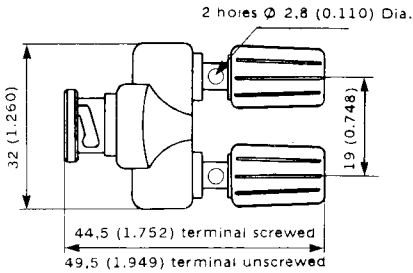
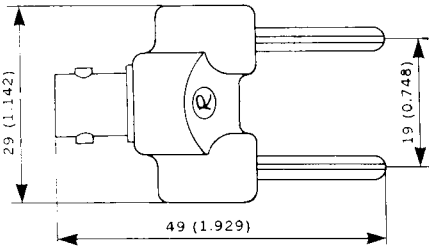
centre contact

ground terminal

: red terminal

: black terminal

► Packaging individually.

Part number	Description	Dimensions
R 191 453	BNC male / 2 – 4 mm dia. sockets adaptor	
R 191 455	BNC female / 2 – 4 mm dia. plugs adaptor	

CHARACTERISTICS

- Dielectric withstanding voltage

– Insulation resistance

: 750 V rms – 50 Hz

: ≥ 5 000 MΩ

Part number	Description	Dimensions
R 191 454	BNC male / 1 – 4 mm dia. socket adaptor	