


QSOP-24 to DIP-24 SMT Adapter (0.635 mm / 25 mil pitch)

REF.	DIMENSIONS					
	mm			inches		
	MIN.	TYP.	MAX.	MIN.	TYP.	MAX.
A		3.80				
B		2.10				
C		0.40				
D		0.235				
E		0.635				
F					0.300	
G					0.100	
H					0.025	

Top View (SMT Footprint)

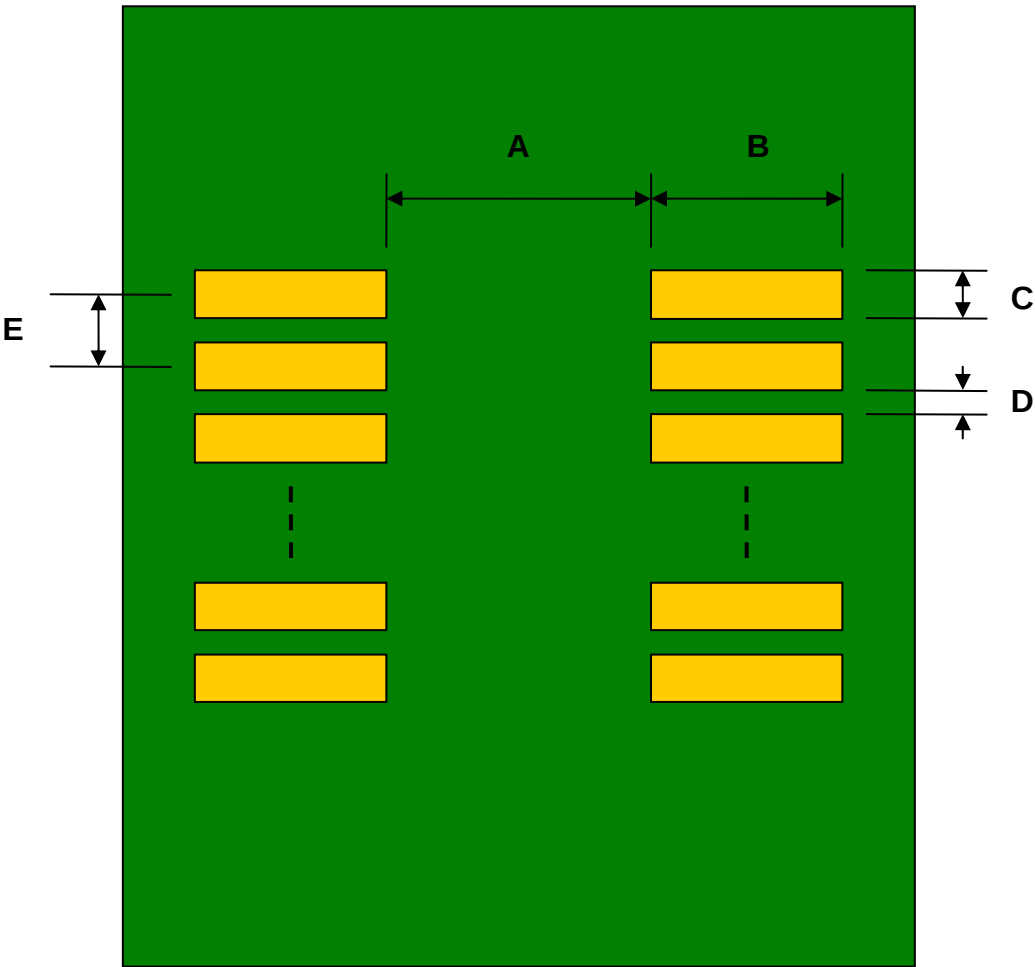

(Representative drawing only - not to scale)

Bottom View (DIP Pins)



(Representative drawing only - not to scale)

Side View (DIP Pins)



(Representative drawing only - not to scale)