

Item number: W21L0C-P06MFG0-620S

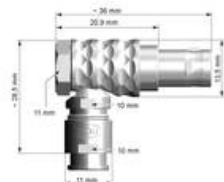


ODU MINI-SNAP® angled connector
6-pin
angled connector - IP 50 with clamping nut for bend relief*
*Please order protective grommets separately
Housing: matt chrome-plated
[Download STP file](#)

[Remember the product](#)

[Download PDF](#)

(Example: image representation of the design)

Dimensions 		Number of poles: 6 poles 		contact insert 6-pin Pin (single contacts) Soldering contact		Coding 0 ° 	
Insulation material:		PEEK					
Contact diameter:		0.7					
Cable diameter:		from 5 mm to 5 mm					
Max. Connection cross section:		AWG 22 / 0.38 mm ²					
Connection		diameter		:	0.85 mm		
Technical specifications							
Continuity resistance		:	<7 μΩ				
Insulation resistance:		10 ^ 16 Ω					
Air and creepage distance:		0.7 mm		according to IEC 60664-1: 2007 (VDE 0110-1: 2008)			
Current load Single contact:		7 A					
Current load compl.		Application		:	4.55 A VDE 0298-4: 2013		
Test		voltage:		1 kV		SAE AS 13441: 2004 method 3001.1	
Rated voltage:		0.33 kV		SAE AS 13441: 2004 method 3001.1			

All dimensions in mm. All illustrations are illustrations. Subject to change.

General information about ODU MINI-SNAP Application
temperature: -40 ° C to + 120 ° C